


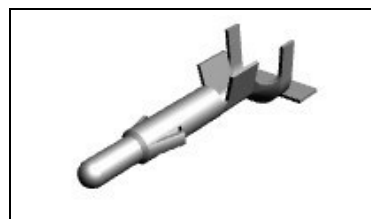

## 926868-1 Product Details

[Share](#) [Print](#) [Email](#)

**926868-1**

### .250" Centerline, 600 V, 19 - 36 A max

Always EU RoHS/ELV Compliant (Statement of Compliance)

**Product Highlights:**

- Universal MATE-N-LOK Product Line
- Wire-to-Wire
- Applies To Wire/Cable
- Contact
- Contact Type = Pin

[View all Features](#)
**Quick Links**

- ▶ [Pricing & Availability](#)
- ▶ [Search for Tooling](#)
- ▶ [View Housings \(206\)](#)
- ▶ [Product Feature Selector](#)
- ▶ [Contact Us About This Product](#)

TE Internal Number: 926868-1

Active

[Add to My Part List](#) [Request Sample](#) [Find Similar Products](#) [Buy Product](#)
**Documentation & Additional Information**

Documents are temporarily unavailable. We are working hard to correct the problem. Please try again later.

**Additional Information:**

- [Product Line Information](#)

**Related Products:**

- [Tooling](#)
- [Housings \(206\)](#)

**Product Features (Please use the Product Drawing for all design activity)**
**Product Type Features:**

- Product Line = Universal MATE-N-LOK
- Product Type = Contact
- Sealed = No
- Wire/Cable Type = Discrete Wire
- CSA File Number = LR 16455

**Mechanical Attachment:**

- Contact Retention = With
- Contact Retention Type = Locking Lance

**Electrical Characteristics:**

- Contact - Rated Current (A) = 19
- Operating Voltage Reference = AC
- Operating Voltage (VAC) = 600

**Termination Features:**

- Wire/Cable Size (mm<sup>2</sup>) = 1.5 - 2.5
- Wire/Cable Size (AWG) = 13.5 - 15.5
- Termination Method to Wire/Cable = Crimp

**Body Features:**

- Wire Type = Stranded

**Contact Features:**

- Contact Type = Pin
- Contact Base Material = CuZn30
- Contact Plating, Mating Area, Material = Pre-Tin
- Multiple Contact Types = Without

**Configuration Features:**

- Strain Relief = Without

**Industry Standards:**

- Agency/Standard = CSA, UL
- [RoHS/ELV Compliance](#) = RoHS compliant, ELV compliant
- [Lead Free Solder Processes](#) = Not relevant for lead free process
- RoHS/ELV Compliance History = Always was RoHS compliant
- VDE Tested = Yes
- UL Rating = Recognized
- UL File Number = E28476
- CSA Rating = Certified

**Environmental:**

- Operating Temperature (°C [°F]) = -55 - +125 [-67 - +257]

**Conditions for Usage:**

- Applies To = Wire/Cable
- Glow Wire Rating = Standard Part - Not Glow Wire
- Accepts Wire Insulation Diameter, Range (mm [in]) = 5.08 [0.200]
- For Use With = Universal MATE-N-LOK Plug or Socket Housing

**Operation/Application:**

- Application Use = Wire-to-Wire

**Packaging Features:**

- Packaging Method = Reel
- Packaging Quantity = 2,500

**Other:**

- Brand = AMP

Feedback

**Corporate Information**

- [About TE](#)
- [Investors](#)
- [News Room](#)
- [Supplier Portal](#)
- [Careers](#)
- [Terms & Conditions](#)

**Quick Links**

- [Distributor Inventory](#)
- [Product Cross Reference](#)
- [Documents & Drawings](#)
- [Product Compliance Support Center](#)
- [Site Map](#)

**Customer Support**

- [Email or Chat With Us](#)
- [Find a Phone Number](#)
- [Knowledge Base](#)
- [Manage Your Account](#)

**Keep Me Informed**