

S7-C




Two pole, one level
Integrated clip and marking labels

10 A


Socket for QRC, 2-Pole Plug-In Relay Types C7-A20, C7-T21, C7-G20, C7-X10, C7-W10

- DIN rail or panel mountable
- Removable labels
- EN/DIN and sequential numbering
- Bridge bar connection in A2

Wiring Diagram

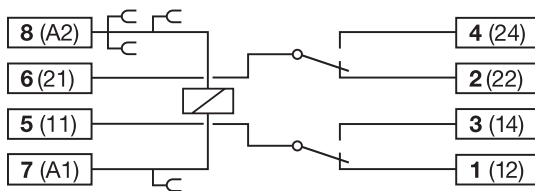

Dimensions - mm

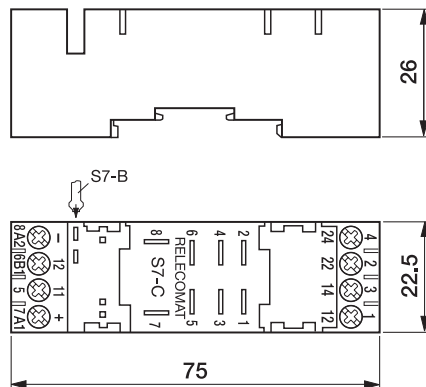

Specifications

Nominal Load: 10 A

Insulation:

Dielectric strength, 1 minute	
Between contacts and coil	2.5 KV
Between all terminals and rail DIN	2.5 KV
Between adjacent poles	2.5 KV

Wire In-Lets Capacity:

Solid wire	4 mm ² or 2 x 1.5 mm ²
Multi-core	16, 18 AWG
Ferrule tip terminals	4 mm ²
Max. screw torque	1.2 Nm
Screw dimensions	M3, Pozi
Integrated hold-down clip	
2 Removable marking labels	

