


Front panels, U profile, shieldable

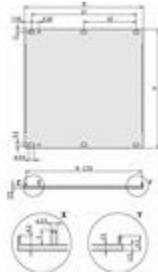

Product illustrations are exemplary illustrations and can deviate from supplied products.

Part no.: 30848-358

Features:

- High stability through U profile
- Front panel, U profile, Al, front anodised, rear conductive, 2 alignment pins pressed-in, stainless steel
- Differences in the finish between 2 ... 12 HP and 14 ... 84 HP

Add to basket



Standard pack quantity 5



Technical information:

| Height | Height | Width | B | b1 | b2 | Alignment pin |
|--------|----------|-------|-----------|-----------|----|---------------|
| 3 U | 128,4 mm | 12 HP | 60,6 (mm) | 45,7 (mm) | | x |

Downloads:

Download CAD data in DWG format ([Log in](#) Required)
Download CAD data in DXF format ([Log in](#) Required)

To gain access to the additional information you must [Log in](#).
If you do not yet have a user name, you may [Register here](#).

Accessories:

| Part no. | Description | |
|------------------|---|---------------|
| 21101-853 | Textile EMC gasket 3 U, PU 10 pieces This accessory qualifies for our Front Panel Express service | Add to basket |
| 21101-854 | Textile EMC gasket 3 U, PU 100 pieces | Add to basket |

Note:

- Standard pack quantity:

- | | |
|--|--|
| | <p>2 to 28 HP: 5 pieces, 42 to 84 HP: 1 piece, supplied in standard pack quantities (SPQ) only</p> <ul style="list-style-type: none">• Please order EMC profile seal and fixing materials separately |
|--|--|