

**TELEPHONE CABINET, TYPE 1**

**FEATURES**

- Continuous hinge
- Tumbler lock with key
- Flush or surface mounting
- 3/4-in.-thick plywood mounting panel included

**SPECIFICATIONS**

- 16, 14 or 12 gauge galvanized steel body, mild steel door

**FINISH**

- ANSI 61 gray polyester powder paint on front only

**ACCESSORIES**

See also Accessories.

Replacement Tumbler Lock


**BULLETIN: T90**
**INDUSTRY STANDARDS**

UL 50, 50E Listed; Type 1; File No. E27567  
 cUL Listed per CSA C22.2 No 40; Type 1; File No. E27567

NEMA/EEMAC Type 1  
 IEC 60529, IP30

**APPLICATION**


Telephone Cabinets house telephone and communication cable terminations as well as electrical controls and instruments in indoor applications.

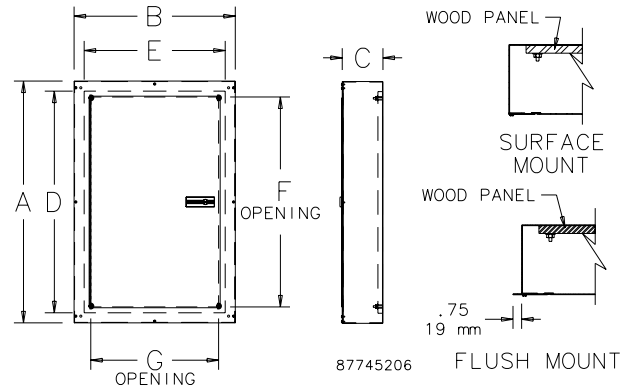
**Standard Product**

Catalog Number	AxBxC in./mm	Mount	Panel Size D x E in./mm	Nominal Door Size F in./mm	Nominal Door Size G in./mm
ATC10104S	10.00 x 10.00 x 4.00	Surface	7.00 x 7.00	6.80	6.75
	254 x 254 x 102		178 x 178	173	171
ATC10104F	10.00 x 10.00 x 4.00	Flush	7.00 x 7.00	6.80	6.75
	254 x 254 x 102		178 x 178	173	171
ATC12124S	12.00 x 12.00 x 4.00	Surface	9.00 x 9.00	8.30	8.25
	305 x 305 x 102		229 x 229	211	210
ATC12124F	12.00 x 12.00 x 4.00	Flush	9.00 x 9.00	8.30	8.25
	305 x 305 x 102		229 x 229	211	210
ATC18124S	18.00 x 12.00 x 4.00	Surface	15.00 x 9.00	14.30	8.25
	455 x 305 x 102		381 x 229	363	210
ATC18124F	18.00 x 12.00 x 4.00	Flush	15.00 x 9.00	14.30	8.25
	455 x 305 x 102		381 x 229	363	210
ATC18184S	18.00 x 18.00 x 4.00	Surface	15.00 x 15.00	14.30	14.25
	455 x 455 x 102		381 x 381	363	362
ATC18184F	18.00 x 18.00 x 4.00	Flush	15.00 x 15.00	14.30	14.25
	455 x 455 x 102		381 x 381	363	362
ATC24184S	24.00 x 18.00 x 4.00	Surface	21.00 x 15.00	20.30	14.25
	610 x 455 x 102		533 x 381	516	362
ATC24184F	24.00 x 18.00 x 4.00	Flush	21.00 x 15.00	20.30	14.25
	610 x 455 x 102		533 x 381	516	362
ATC24244S	24.00 x 24.00 x 4.00	Surface	21.00 x 21.00	19.30	19.14
	610 x 610 x 102		533 x 533	490	486
ATC24244F	24.00 x 24.00 x 4.00	Flush	21.00 x 21.00	19.30	19.14
	610 x 610 x 102		533 x 533	490	486
ATC30244S	30.00 x 24.00 x 4.00	Surface	27.00 x 21.00	25.30	19.14
	762 x 610 x 102		686 x 533	643	486
ATC30244F	30.00 x 24.00 x 4.00	Flush	27.00 x 21.00	25.30	19.14
	762 x 610 x 102		686 x 533	643	486
ATC30304S	30.00 x 30.00 x 4.00	Surface	27.00 x 27.00	25.30	25.14
	762 x 762 x 102		686 x 686	643	639
ATC36244S	36.00 x 24.00 x 4.00	Surface	33.00 x 21.00	31.30	19.14
	914 x 610 x 102		838 x 533	795	486
ATC36244F	36.00 x 24.00 x 4.00	Flush	33.00 x 21.00	31.30	19.14
	914 x 610 x 102		838 x 533	795	486

Catalog Number	AxBxC in./mm	Mount	Panel Size D x E in./mm	Nominal Door Size F in./mm	Nominal Door Size G in./mm
ATC36364S	36.00 x 36.00 x 4.00 914 x 914 x 102	Surface	33.00 x 33.00 838 x 838	31.30 795	31.14 791
ATC36364F	36.00 x 36.00 x 4.00 914 x 914 x 102	Flush	33.00 x 33.00 838 x 838	31.30 795	31.14 791
ATC12126S	12.00 x 12.00 x 6.00 305 x 305 x 152	Surface	9.00 x 9.00 229 x 229	8.30 211	8.25 210
ATC12126F	12.00 x 12.00 x 6.00 305 x 305 x 152	Flush	9.00 x 9.00 229 x 229	8.30 211	8.25 210
ATC18126S	18.00 x 12.00 x 6.00 455 x 305 x 152	Surface	15.00 x 9.00 381 x 229	14.30 363	8.25 210
ATC18126F	18.00 x 12.00 x 6.00 455 x 305 x 152	Flush	15.00 x 9.00 381 x 229	14.30 363	8.25 210
ATC18186S	18.00 x 18.00 x 6.00 455 x 455 x 152	Surface	15.00 x 15.00 381 x 381	14.30 363	14.25 362
ATC18186F	18.00 x 18.00 x 6.00 455 x 455 x 152	Flush	15.00 x 15.00 381 x 381	14.30 363	14.25 362
ATC24186S	24.00 x 18.00 x 6.00 610 x 455 x 152	Surface	21.00 x 15.00 533 x 381	20.30 516	14.25 362
ATC24186F	24.00 x 18.00 x 6.00 610 x 455 x 152	Flush	21.00 x 15.00 533 x 381	20.30 516	14.25 362
ATC24246S	24.00 x 24.00 x 6.00 610 x 610 x 152	Surface	21.00 x 21.00 533 x 533	19.30 490	19.14 486
ATC24246F	24.00 x 24.00 x 6.00 610 x 610 x 152	Flush	21.00 x 21.00 533 x 533	19.30 490	19.14 486
ATC30246S	30.00 x 24.00 x 6.00 762 x 610 x 152	Surface	27.00 x 21.00 686 x 533	25.30 643	19.14 486
ATC30306S	30.00 x 30.00 x 6.00 762 x 762 x 152	Surface	27.00 x 27.00 686 x 686	25.30 643	25.14 639
ATC30306F	30.00 x 30.00 x 6.00 762 x 762 x 152	Flush	27.00 x 27.00 686 x 686	25.30 643	25.14 639
ATC36246S	36.00 x 24.00 x 6.00 914 x 610 x 152	Surface	33.00 x 21.00 838 x 533	31.30 795	19.14 486
ATC36246F	36.00 x 24.00 x 6.00 914 x 610 x 152	Flush	33.00 x 21.00 838 x 533	31.30 795	19.14 486
ATC36306S	36.00 x 30.00 x 6.00 914 x 762 x 152	Surface	33.00 x 27.00 838 x 686	31.30 795	25.14 639
ATC36306F	36.00 x 30.00 x 6.00 914 x 762 x 152	Flush	33.00 x 27.00 838 x 686	31.30 795	25.14 639
ATC36366S	36.00 x 36.00 x 6.00 914 x 914 x 152	Surface	33.00 x 33.00 838 x 838	31.30 795	31.14 791
ATC36366F	36.00 x 36.00 x 6.00 914 x 914 x 152	Flush	33.00 x 33.00 838 x 838	31.30 795	31.14 791
ATC36308S	36.00 x 30.00 x 8.00 914 x 762 x 203	Surface	33.00 x 27.00 838 x 686	31.30 795	25.14 639
ATC36308F	36.00 x 30.00 x 8.00 914 x 762 x 203	Flush	33.00 x 27.00 838 x 686	31.30 795	25.14 639

**REPLACEMENT TUMBLER LOCK**

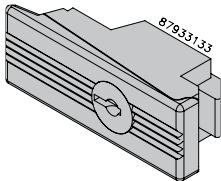

Tumbler lock including key available for replacement of door latch (order separately).

**BULLETIN: T90**

Catalog Number	Description
ATCL	Keyed Tumbler Lock