



**Miniature Audio
Potted
P.C. Board Mount**

- Home
- Products
- Distributors
- Technical
- Contact Us
- Other Options

Path: [Home](#) > [Transformer Index](#) > [Audio](#) > P.C. Board Mount - Miniature - Potted

Close-Up



click to enlarge

**Caliper in photo
opened to 1" (25.4mm)**



click to enlarge



Key Features:

- Pin type, miniature size, P.C. board mount, net weight of only 0.1 oz.
- Rugged potted construction produces a completely sealed unit withstanding severe environmental conditions.
- Secondary may be used as primary and primary as secondary.
- Power level: Minimum frequency range: 300 Hz. to 100 Khz. +/- 0.5 db @ 100 mw
 - Frequency range @ +10 dbm is 200 Hz. to 100 Khz. +/- 0.5 db
 - Frequency range @ +15 dbm is 200 Hz. to 100 Khz. +/- 0.5 db
 - Frequency range @ +20 dbm is 300 Hz. to 100 Khz. +/- 0.5 db
 - Frequency measurements with no D.C. current saturation.
- See data sheets for more detailed information.

Part Number	Nominal Impedance (Ohms)		Nominal Resistance (Ohms)		Data Sheet	Useful Impedance Range (Ohms)	
	Primary	Secondary	Primary	Secondary	Reader File	Pri./Sec. to Pri./Sec.	
101D	300 ct	600 ct	20.4	54	- 	150/300	600/1200
101F	600 ct	600 ct	44	52	 383K	300/300	1200/1200
101H	1200 ct	600 ct	80	53	- 	600/300	2400/1200
101J	2500 ct	600 ct	150	54	- 	1250/300	5000/1200

101P	300 ct	50 ct	20.4	4.8	-	150/25	600/100
101R	600 ct	50 ct	44	4.7	-	300/25	1200/100
101V	2500 ct	50 ct	150.7	4.9	-	1250/25	5000/100

Mechanical & Schematic Data:

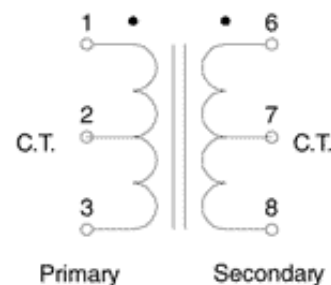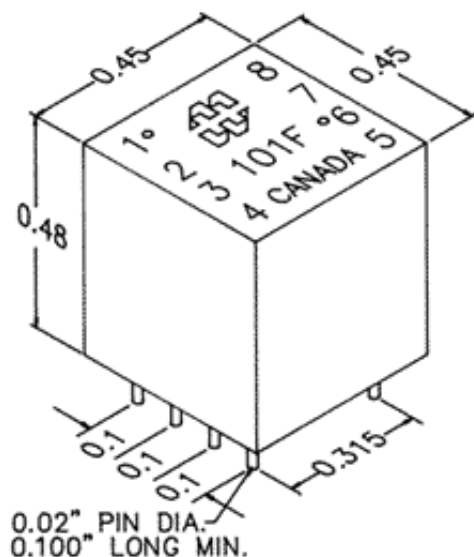

Downloads



Catalog page(s) on JUST this series (239K)

Exactly what you are looking for???

Link to our stocking distributors - most have "on-line" pricing, stock check and ordering!!!

Our Distributors

[Order from your favorite distributor](#)

[Home](#) | [Products](#) | [Distributors](#) | [Technical](#) | [Contact Us](#) | [Other Options](#)

