

Threaded strip


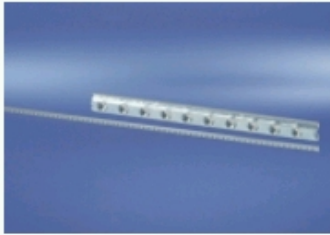


Illustration shows 84 HP threaded insert

Thread spacing: 1 HP (5.08 mm)

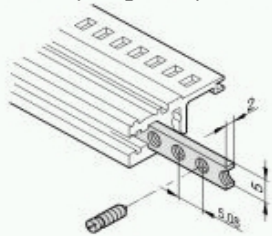

Part no.: 34561-340

Features:

- Can be used for all horizontal rails
- The collar screws for mounting partial width front panels must be 12.3 mm long.
-
-

Add to basket



Standard pack quantity 10



Technical information:

Thread	Usable width	Length
M2,5	40 HP	207,78 mm

Downloads:

3D PDF with CAD data (STEP/DWG/DXF/PDF) ([Log in](#) Required)
 CAD data in STEP 3D format ([Log in](#) Required)

To gain access to the additional information you must [Log in](#).
 If you do not yet have a user name, you may [Register here](#).

Delivery comprises:

Item	Qty	Description
1	1	Threaded inserts, zinc-plated steel

Accessories:

Part no.	Description	
21100-276	Grub screw M2,5 × 8, PU 100 pieces, finish nickel-plated	Add to basket