


# 6 LED FESTOON LAMP

## FEATURES

- Non-Polarized
- 12V and 24V AC and DC Operation
- High Efficacy - 90 Lm/Watt Cool White
- 86 Lm/Watt Neutral White
- 80 Lm/Watt Warm White
- Standard Size - Fits JKL Socket #2910F-42

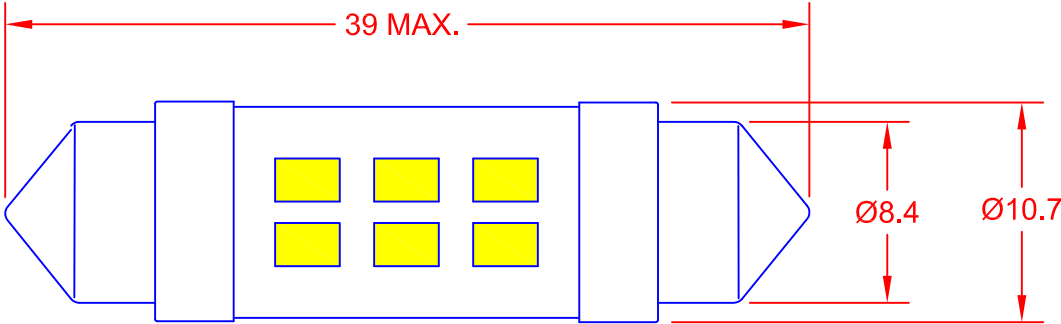

JKL PART NUMBER	Color	Input Voltage (V AC/DC)			Power Typ. (W)	Current Typ. (mA)	Radiance Angle (Deg.)	CCT(K)	Lumen Flux (lm)	Operating Temp. (deg. C)		
		Min.	Typ.	Max.						Min.	Typ.	Max.
LE-0909-11CW	Cool White	--	12	24	0.5	45	120	6000	45	-20	25	40
LE-0909-11NW	Neutral White	--	12	24	0.5	45	120	4500	43	-20	25	40
LE-0909-11WW	Warm White	--	12	24	0.5	45	120	3000	40	-20	25	40

REV. NO.	DESCRIPTION/ECO NUMBER	APPV'D DATE
A	CHANGE MOL TO 39 MAX.	11/11/13
	RELEASED	6/20/11

METRIC

THIRD ANGLE PROJECTION

DIMENSIONS ARE IN MILLIMETERS  
TOLERANCE UNLESS OTHERWISE SPECIFIED  
1 PL +/- 0.5  
2 PL +/- 0  
ANGLE +/- 0

DRAWN BY L. WENGSTROM  
APPV'D BY L.R. DATE 11/11/13

- CAD DRAWING -  
MANUAL REVISIONS NOT PERMITTED

**JKL** COMPONENTS CORPORATION

TITLE: 6 LED FESTOON LAMP

SIZE: A FSCM NO. 55335 DRAWING NO. LE-0909-11

SCALE: NONE RELEASED DATE 6/20/11 REVISION DATE 11/11/13 REV. NO. A SHEET 1 OF 1