


# 6 LED FESTOON LAMP

## FEATURES

- Non-Polarized
- 12V and 24V AC and DC Operation
- High Efficacy - 90 Lm/Watt Cool White
- 86 Lm/Watt Neutral White
- 80 Lm/Watt Warm White
- Standard Size - Fits JKL Socket #2910F-47

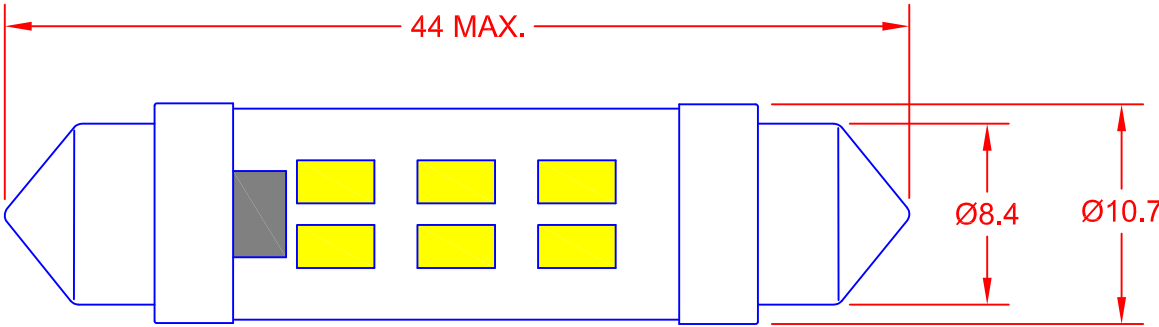

JKL PART NUMBER	Color	Input Voltage (V AC/DC)			Power Typ. (W)	Current Typ. (mA)	Radiance Angle (Deg.)	CCT(K)	Lumen Flux (lm)	Operating Temp. (deg. C)		
		Min.	Typ.	Max.						Min.	Typ.	Max.
LE-0909-14CW	Cool White	--	12	24	0.5	45	120	6000	45	-20	25	40
LE-0909-14NW	Neutral White	--	12	24	0.5	45	120	4500	43	-20	25	40
LE-0909-14WW	Warm Write	--	12	24	0.5	45	120	3000	40	-20	25	40

		<b>METRIC</b> DIMENSIONS ARE IN MILLIMETERS TOLERANCE UNLESS OTHERWISE SPECIFIED 1 PL +/- 0.5 2 PL +/- 0 ANGLE +/- 0		<b>JKL COMPONENTS CORPORATION</b>			
THIRD ANGLE PROJECTION		DRAWN BY L. WENGSTROM		APP'VD BY DATE L.R. 11/11/13		TITLE <b>6 LED FESTOON LAMP</b>	
A CHANGE MOL TO 44 MAX. RELEASED		11/11/13 6/20/11		SIZE <b>A</b>		FSCM NO. <b>55335</b>	
REV. NO. DESCRIPTION/ECO NUMBER		APP'VD DATE		SCALE NONE		DRAWING NO. LE-0909-14	
- CAD DRAWING - MANUAL REVISIONS NOT PERMITTED				RELEASED DATE 6/20/11		REVISION DATE 11/11/13	
				REV. NO. <b>A</b>		SHEET 1 OF 1	