


**52057-102LF - METRAL® : 4000 Series
Receptacle, Right Angle, 5 Row, Press-Fit,
30 Position**

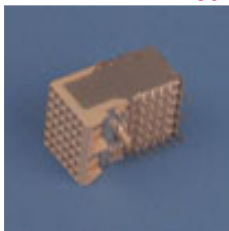

www.fci.com

Mating Half

- [55003-101004LF](#)
- [55003-501003LF](#)
- [59566-5003LF](#)

Specifications

Dimensional	
Length (Tail)	See Customer Drawing
Thickness (Board)	See Customer Drawing
General	
Contact type	Signal
Number of contacts (Total)	30
Number of ports (per row)	6
Number of rows	5
Orientation	Right Angle
Product Type	Receptacle
Series	4000
Termination Style	Press-Fit
Application Equipment	5 Row Right Angle 4000 Series Receptacle Insert Tool 5 Row Right Angle 4000 Series Receptacle Removal Tool
Mounting	
Termination	Board
Other Features	
Packaging (Type)	Tube
Physical	
Color (Housing)	Natural
Material (Contact)	Copper Alloy
Material (Housing)	Glass - Filled LCP
Plating (Contact area)	See Customer Drawing
Plating (Tail)	Matte-Tin