

JB hinge cover junction box




System accessories Page 531

Material:
Carbon steel
Enclosure: 16 ga (1.5 mm)

Configuration:
Door with 180° left-hand hinges,
includes screwdriver insert.

Surface finish:
Enclosure and door:
Powder-coated
on the outside in textured
RAL 7035 (light grey)

Protection rating:
UL Type 12
(IP 54 to EN 60 529/10.91)
UL/cUL Type 3R
UL/cUL Type 4
(IP 66 to EN 60 529/10.91)
UL File #: E170282

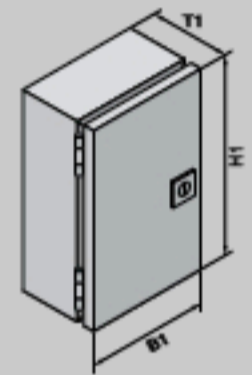

Note: zinc-plated enclosure mounting panel sold separately (see below)

Depth: 3 - 4" (75 - 100 mm), Height: 5 - 7" (135 - 185 mm)

Height (H1) inches (mm)	PU	4 (100)	6 (150)	6 (150)	6 (150)	8 (200)	8 (200)	Page
Width (B1) inches (mm)		4 (100)	4 (100)	4 (100)	6 (150)	6 (150)	8 (200)	
Depth (T1) inches (mm)		3 (75)	3 (75)	4 (100)	4 (100)	4 (100)	4 (100)	
Panel Height inches (mm)		-	5 (135)	5 (135)	5 (135)	7 (185)	7 (185)	
Panel Width inches (mm)		-	3 (75)	3 (75)	5 (125)	5 (125)	7 (175)	
Part No.	1	JB040403HC	JB060403HC	JB060404HC	JB060604HC	JB080604HC	JB080804HC	
Weight lb (kg)		2 (0.9)	3 (1.4)	3 (1.4)	4 (1.6)	5 (2.0)	6 (2.5)	

Accessories

Mounting panel	1	-	JBMP0604	JBMP0606	JBMP0806	JBMP0808	633
Wallmount bracket	4	1590.000					628

Depth: 4 - 6" (100 - 150 mm), Height: 10 - 12" (250 - 300 mm)

Height (H1) inches (mm)	PU	10 (250)	12 (300)	12 (300)	8 (200)	10 (250)	10 (250)	Page
Width (B1) inches (mm)		8 (200)	6 (150)	10 (250)	6 (150)	8 (200)	10 (250)	
Depth (T1) inches (mm)		4 (100)	4 (100)	5 (125)	6 (150)	6 (150)	6 (150)	
Panel Height inches (mm)		9 (235)	11 (285)	11 (285)	7 (185)	9 (235)	9 (235)	
Panel Width inches (mm)		7 (175)	5 (125)	9 (225)	5 (125)	7 (175)	9 (225)	
Part No.	1	JB100804HC	JB120604HC	JB121005HC	JB080606HC	JB100806HC	JB101006HC	
Weight lb (kg)		8 (3.4)	6 (2.7)	9 (4.1)	6 (2.5)	8 (3.4)	9 (3.9)	

Accessories

Mounting panel	1	JBMP1008	JBMP1206	JBMP1210	JBMP0806	JBMP1008	JBMP1010	633
Wallmount bracket	4	1590.000					628	

JB hinge cover junction box

Depth: 3 - 4" (75 - 100 mm), Height: 5 - 7" (135 - 185 mm)

Height (H1) inches (mm)	PU	12 (300)	12 (300)	14 (350)	16 (400)	12 (300)	16 (400)	16 (400)	Page
Width (B1) inches (mm)		10 (250)	12 (300)	12 (300)	14 (350)	10 (250)	14 (350)	14 (350)	
Depth (T1) inches (mm)		6 (150)	6 (150)	6 (150)	6 (150)	8 (200)	8 (200)	10 (250)	
Panel Height inches (mm)		11 (285)	11 (285)	13 (335)	15 (385)	11 (285)	15 (385)	15 (385)	
Panel Width inches (mm)		9 (225)	11 (275)	11 (275)	13 (325)	9 (225)	13 (325)	14 (350)	
Part No.	1	JB121006HC	JB121206HC	JB141206HC	JB161406HC	JB121008HC	JB161408HC	JB161410HC	
Weight lb (kg)		10 (4.5)	11 (5.0)	12 (5.5)	15 (6.8)	11 (5.0)	17 (7.7)	19 (8.6)	
Accessories									
Mounting panel	1	JBMP1210	JBMP1212	JBMP1412	JBMP1614	JBMP1210	JBMP1614	JBMP1614	633
Wallmount bracket	4	1590.000							628



Rittal Australia

RITTAL Pty. Ltd.
 130 – 140 Parraweena Road
 Miranda NSW 2228
 Phone: +61 (2) 9525 2766
 Fax: +61 (2) 9525 2888
 E-mail: info@rittal.com.au • www.rittal.com.au