 


POWER-COMBICON Cable Housings



These ergonomically designed cable housings serve as strain relief for the conductors screwed to the plugs. Four versions are available:

- KGG-PC 4/... , 3-5 positions, with straight cable connection,
- KGG-PC 4/...-F, 3-5 positions, with straight cable connection and screw flange,
- KGS-PC 4/... , 6-12 positions, with angled cable connection and
- KGS-PC 4/...-F, 6-12 positions, with angled cable connection and screw flange.

The standard PC plug with screw connection can be used in all versions.

Strain relief for conductors of 4 to 16 mm Ø is provided by a clamp in the housing. Transparent labels and marker strips are included.


Several plugs can be aligned directly beside each other thanks to the cable routing. The half shell housings are screwed together securely.

Type of housing

ABS, see page 263
color: green


POWER-COMBICON plugs see pages 158 and 159.


Articles printed in bold can be delivered at short notice.

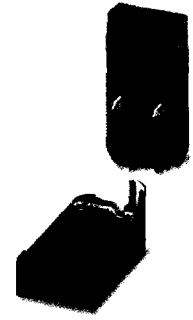


KGG-PC 4/...

3-5 positions, with straight cable connection


Description	No. of positions	Dim. a [mm]	Type	Enclosed housing	
				Order No.	Pcs. Pkt.
Cable housing , for cable diameters of 4-11 mm, cable diameters of 6-13.5 mm, incl. cable clamp, transparent label carrier and marker strips, color: green	3	24.66	KGG-PC 4/3	18 37 22 7	10
	4	32.28	KGG-PC 4/4	18 37 23 0	
	5	39.90	KGG-PC 4/5	18 37 24 3	
Cable housing , as above, however, with screw flange, color: green	3	24.66			
	4	32.28			
	5	39.90			
Cable housing , for cable diameters of 6-16 mm, transparent label carrier and marker strips are enclosed, color: green	6	47.52			
	7	55.14			
	8	62.76			
	9	70.38			
	10	78.00			
	11	85.62			
Cable housing , as above, however, with screw flange, for cable diameters 6-16 mm, color: green	6	47.52			
	7	55.14			
	8	62.76			
	9	70.38			
	10	78.00			
	11	85.62			
(1) Transparent label carrier , can be marked with marker strips SBS 2,5/7,5			 KGS-MSTB 2,5/DST	17 84 91 4	10
(2) Marker strips , 10-section, perforated, white plastic, unprinted for individual labelling, lettering area 15 x 7.5 mm			SBS 2,5/7,5	10 07 60 4	10

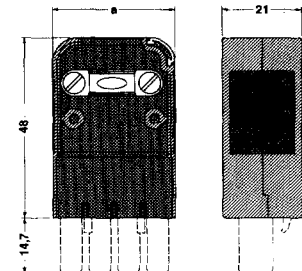

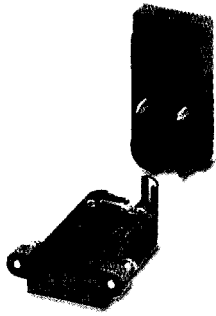


KGG-PC 4/...-F

3-5 positions, with straight cable connection and screw flange

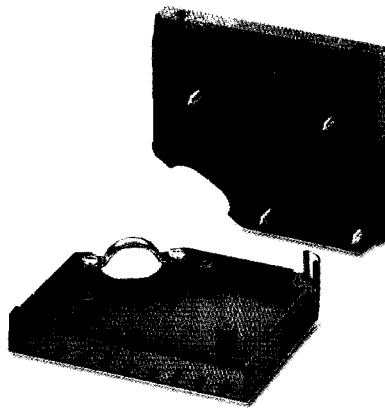

KGS-PC 4/...

6-12 positions, with angled cable connection

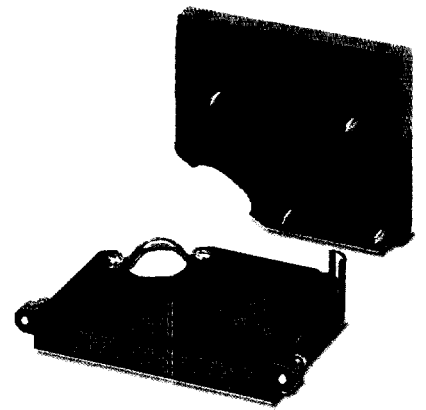

KGS-PC 4/...-F

6-12 positions, with angled cable connection and screw flange

Type	Enclosed housing		Type	Enclosed housing		Type	Enclosed housing	
	Order No.	Pcs. Pkt.		Order No.	Pcs. Pkt.		Order No.	Pcs. Pkt.
KGG-PC 4/3-F KGG-PC 4/4-F KGG-PC 4/5-F	18 37 32 4 18 37 33 7 18 37 34 0	10	KGS-PC 4/6 KGS-PC 4/7 KGS-PC 4/8 KGS-PC 4/9 KGS-PC 4/10 KGS-PC 4/11 KGS-PC 4/12	18 37 25 6 18 37 26 9 18 37 27 2 18 37 28 5 18 37 29 8 18 37 30 8 18 37 31 1	10	KGS-PC 4/6-F KGS-PC 4/7-F KGS-PC 4/8-F KGS-PC 4/9-F KGS-PC 4/10-F KGS-PC 4/11-F KGS-PC 4/12-F	18 37 35 3 18 37 36 6 18 37 37 9 18 37 38 2 18 37 39 5 18 37 40 5 18 37 41 8	10
KGS-MSTB 2,5/DST	17 84 91 4	10	KGS-MSTB 2,5/DST	17 84 91 4	10	KGS-MSTB 2,5/DST	17 84 91 4	10
SBS 2,5/7,5	10 07 60 4	10	SBS 2,5/7,5	10 07 60 4	10	SBS 2,5/7,5	10 07 60 4	10

