


PLASTIC STANDARD SERIES CABLE GLANDS

Water tight, easy to assemble, good strain relief, wide clamping range, multipurpose applications, easy handling.

Technical data:

Material	Polyamide 6
Color	RAL 7001 (Gray) RAL 9005 (Black)
Protection Class	IP 68.5 bar
Temp. Range	-30°C to +80°C permanent
Oper. Temperature	Up to +150°C intermittent
Seal	Neoprene

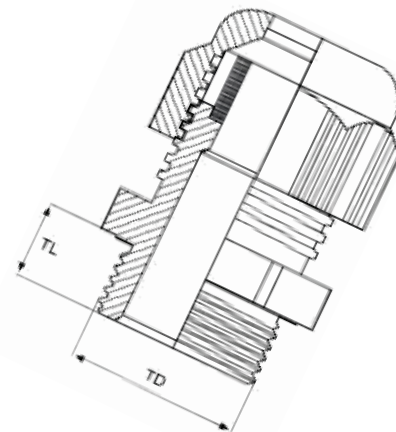

NPT Size	Part Number Gray	Part Number Black	Thread Length	Wrenching Flats	Diameter Range
NPT					
NPT 3/8	BSPA-01	BSPA-21	0.59	0.866	.197 - .394
NPT 1/2	BSPB-02	BSPB-22	0.59	0.945	.236 - .472
NPT 3/4	BSPD-03	BSPD-23	0.59	1.299	.511 - .709
NPT 1	BSP-04	BSP-24	0.709	1.654	.709 - .984
NPT 1 1/4	BSPE-05	BSPE-25	0.709	2.087	.709 - .984
NPT with Reducer Bushings					
NPT 3/8	BSPA-01R	BSPA-21R	0.59	0.866	.118 - .276
NPT 1/2	BSPB-02R	BSPB-22R	0.59	0.945	.197 - .354
NPT 3/4	BSPD-03R	BSPD-23R	0.59	1.299	.354 - .630
NPT 1	BSP-04R	BSP-24R	0.709	1.654	.472 - .787
NPT 1 1/4	BSPE-05R	BSPE-25R	0.709	2.087	.472 - .787

4

Various colors, materials, and sizes available upon request

Email: info@sabcable.com



Website: www.sabcable.com