




Series
TS-Probes

Digital Temperature Switch Probes & Accessories

Probes to Be Used with TS2, TSS2, TSWB, TSW, TS3, TSX3, and 40M

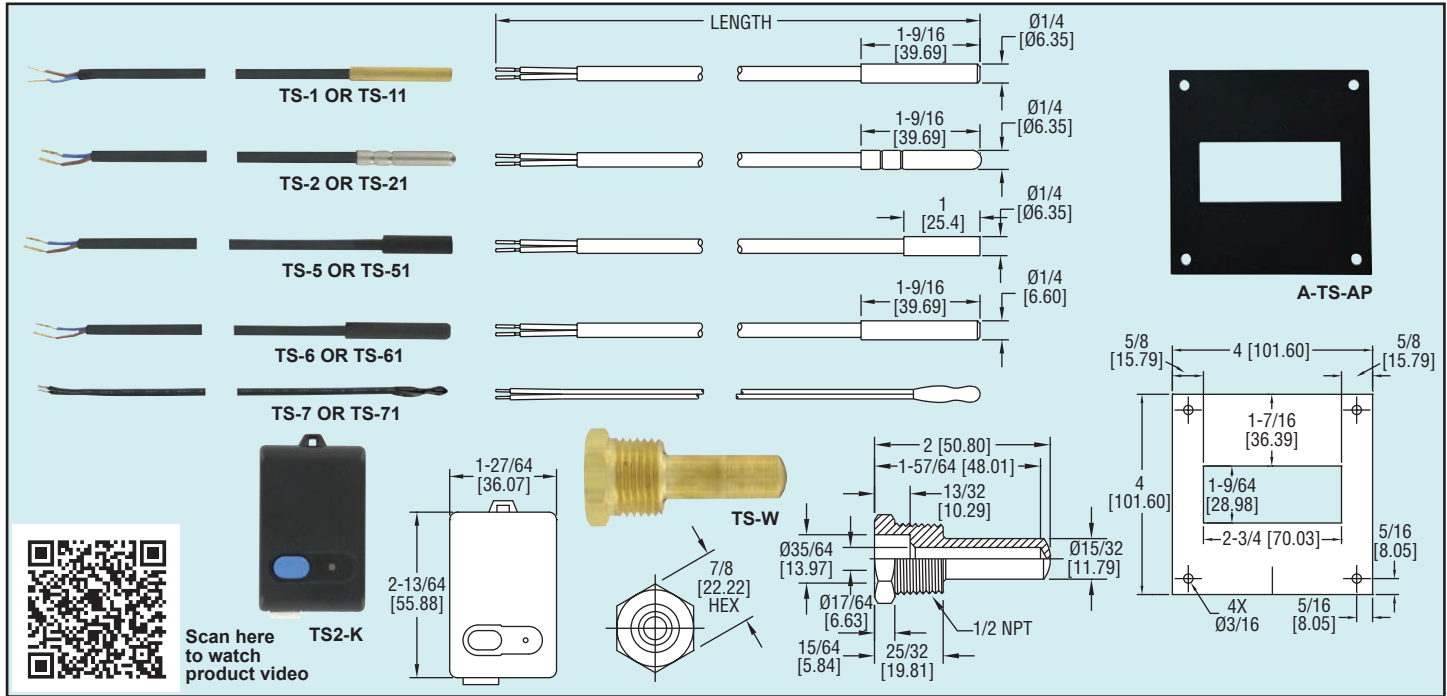

Model	Sensor	Cap Material	Length ft (m)
TS-1	PTC	Brass	5 (1.5)
TS-11	PTC	Brass	10 (3)
TS-2	PTC	Stainless Steel	5 (1.5)
TS-21	PTC	Stainless Steel	10 (3)
TS-5	PTC	PVC	5 (1.5)
TS-51	PTC	PVC	10 (3)
TS-6	PTC	Polyamide Resin Coated Brass	5 (1.5)
TS-61	PTC	Polyamide Resin Coated Brass	10 (3)
TS-7	NTC	None	5 (1.5)
TS-71	NTC	None	10 (3)

SPECIFICATIONS

Sensor: PTC or NTC (depending on model).

Operating Temperature: -58 to 221°F (-50 to 105°C).

Accuracy: ±2°C at 25°C.

Response Time: 15 seconds (in air).

Cable: PVC.

Protection: IP67 (NEMA 6).

ACCESSORIES

A-TS-AP, 1/4 DIN Adapter Plate

TS-W, Brass Thermowell (for use with TS-1, TS-11, TS-2, TS-21)

TS2-K, Configuration Key