

MaxOffice 600

Orion Power Systems

Cost effective power protection rated at 600VA



The Orion Power Systems MaxOffice 600 is the most cost effective solution for protecting small/home office computers, telephone, security, and peripheral equipment.

Ideally suited for:

- Point of Sale
- Computers
- Data processing
- Phone Systems
- Peripherals

Product Snapshot

Power Rating	600VA/300W
Input Voltage Range	120 VAC (Nominal)
Output Voltage Range	120 VAC (Nominal)
Frequency (HZ)	50/60 HZ
Topology	Stand By
Configuration	Flat with wall mount capability
Surge Protection	860 joules

Battery Backup time in Minutes *

Load	Internal Batteries
MXO600U	
Typical computer	20 min.


* Calculations are approximate and will vary based on battery age, temperature, etc.

Features

- Ultimate 860 joule surge protection
- Smart Microprocessor Control
- RS232 and USB Communication Port
- Power Monitoring and Shutdown Software
- Wall mount capability
- Smart Battery Management
- 37 Month Silver Warranty on Electronics and battery
- Network / Phone Surge protection (RJ11/45)
- \$50,000 Load Protection Guarantee



MaxOffice has the features you need.

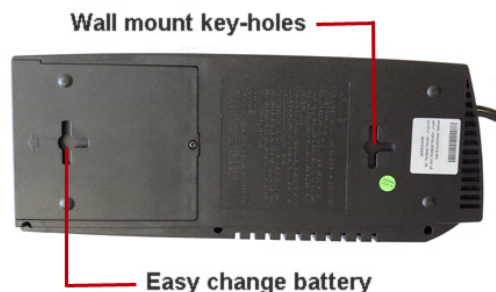

Specifications:

MaxOffice 600: 120V 50/60HZ

Model #	Rating (VA/Watts)	Input	Output Receptacles	Dim. HxWxD (in.)	Weight (lbs.)
MXO600U	600/300	5-15P	(3) 5-15R surge only (3) 5-15R battery & surge	3.2 x 5 x 12	6

Electrical Input

Nominal Voltage	120V
Voltage Range	84~147
Frequency (HZ)	50/60Hz

Electrical Output

Voltage – On Inverter	120V +/- 10%
Frequency (HZ)	50/60Hz, (± 1 Hz)
Wave Form	Simulated Sine Wave

Warranty and Protection

Warranty	37 month Silver warranty on electronics and batteries.
Load Protection Guarantee	\$ 50,000 (U.S. only)

Communications

Interface Type	1 USB port 1 RS-232
Monitoring / Shutdown Software	Windows 95/98/NT/2000/XP /Vista/7. Included at no charge.

Environmental

Operation Temperature	+32°F to + 104°F (0°C to + 40°C)
Relative Humidity	0% to 95%, non-condensing

Standards and Certification

Quality Assurance	ISO 9001 Certified
EMC	FCC, Class A
Markings	UL 1778

Battery

Type	Sealed lead acid
Recharge time	8 hours to 90%
Voltage	12VDC



Orion Power Systems, Inc.

5771 Mining Terrace Suite 201
Jacksonville, FL 32257
877.385.1654
www.orionpowersystems.com