


PRIMARY ARE 13AWG SOLID SELF LEADS
 SECONDARY ARE 15AWG SOLID SELF LEADS

ALL LEADS OUT 9"-10" AND
 STRIPPED 0.5" MIN.

WEIGHT: 20.08lbs +/- 4%

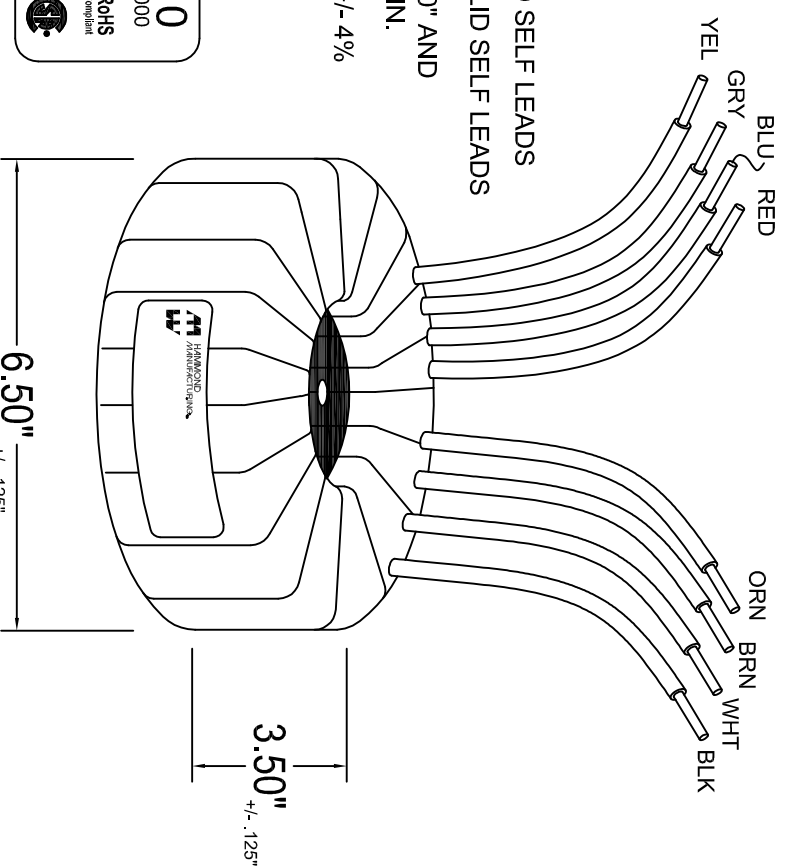

182S110
 50/60Hz VA:1000

CE **RoHS**
 Compliant

MADE IN CANADA DATE PB

SUPPLIED WITH: EPOXY FILLED CENTER WITH A 13/32 MOUNTING HOLE.
 ONE 0.093" T X 4.75" OD RUBBER WASHER FIXED TO THE BOTTOM.
 ONE 3/8-16 BOLT 3.50" LONG WITH A LOCK WASHER AND 3/8-16 HEX NUT.

ELECTRICAL DATA:	
TESTS	ACCEPTANCE CRITERIA
Sec. N.L.V	@ 117V, 60Hz
	BLK & BRN to WHT & ORN
OR	@ 234V, 50Hz
	BLK to ORN (Connected BRN & WHT)
	RED - BLU ±2%
	RED - BLU 113.72 V
	GRY - YEL ±2%
	GRY - YEL 113.72 V
POLARITY	BLK, BRN, RED and GRY. ADDITIVE
DCR	BLK - WHT 0.340 Ohms ±20%
	BRN - ORN 0.340 Ohms ±20%
	RED - BLU 0.385 Ohms ±20%
	GRY - YEL 0.385 Ohms ±20%
HIPOT	PRIMARY - SECONDARY 4000V, 60Hz, 1 SEC
	PRIMARY - PRIMARY 600V, 60Hz, 1 SEC
	SECONDARY - SECONDARY 600V, 60Hz, 1 SEC

PROPERTY AND COPYRIGHT NOTICE

THIS DRAWING AND THE INFORMATION IT CONVEYS ARE THE PROPERTY OF HAMMOND MANUFACTURING. IT MAY NOT BE REPRODUCED, TRANSMITTED OR USED IN ANY MANNER WHATSOEVER WITHOUT THE WRITTEN PERMISSION OF HAMMOND MANUFACTURING.

TOROID POWER TRANSFORMER

182S110

DATE: 06/05/2015

APPROVED: G. GRAY