


Capacitor, film, 40 uF, +/-5% Tol, 470VAC, Motor Run

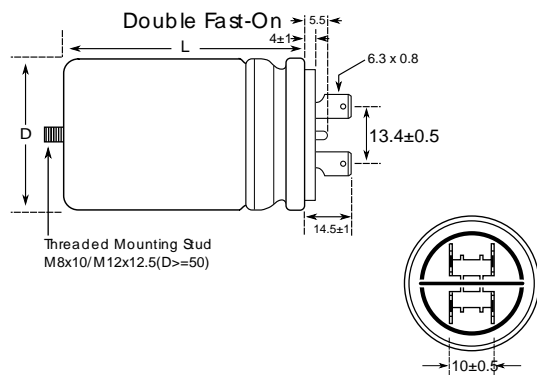

Dimensions (mm)

Symbol	Dimension	Tolerance
D	45	+1
L	98	+/-2

Packaging Specifications

Package Kind:	Bulk
---------------	------

General Information

Supplier:	KEMET
Construction:	Aluminum Case Plastic Cover with Spun Seal

Specifications

Capacitance:	40 uF
Voltage AC:	470VAC
Tolerance:	+/-5%
Dielectric:	Film-Foil Polypropylene
Rated Temperature:	85C
Life @ rated temp:	10000 Hrs
Life @ alt temp:	30000 Hrs
Life alt temp:	85C
Life alt conditions:	420V
Application:	Motor Run
Body Type:	Round Can
Temperature Range:	-25/+85C
Lead Type:	Fast-on
Lead Specification:	2+2
Mounting Type:	Bolt: M8x10
Maximum dVdT:	15 v/us

Agency Approvals

Approval UL:	Yes
Approval VDE:	Yes
Approval CQC:	Yes
Approval Notes:	CSA(240Vac)
Safety Class:	P2