


PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number: [0740990606](#)
Status: **Active**
Overview: [SL Modular Connectors](#)
Description: SL Wire-to-Board Header, Surface Mount, Single Row, Vertical, 6 Circuits, Tin (Sn) Plating, Packaging Tape and Reel with Pick-and-Place Cap

Documents:

3D Model	Product Specification TS-70541-001-001 (PDF)
Drawing (PDF)	Product Specification TS-70541-100-001 (PDF)
Product Specification PS-70400-001 (PDF)	Packaging Specification PK-70873-9000 (PDF)
Product Specification PS-70541-001 (PDF)	RoHS Certificate of Compliance (PDF)

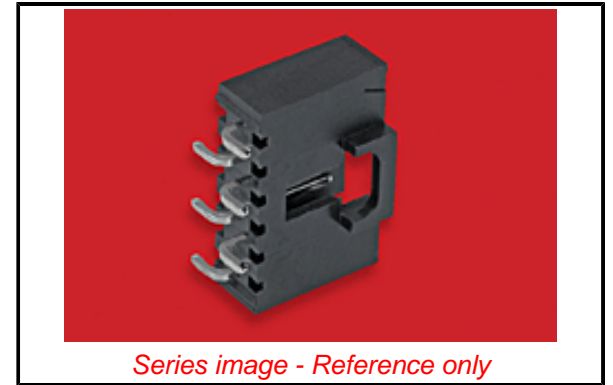

Agency Certification

CSA	LR19980
UL	E29179

General

Product Family	PCB Headers
Series	74099
Application	Signal, Wire-to-Board
Overview	SL Modular Connectors
Product Name	SL
UPC	887191449845

Physical

Breakaway	No
Circuits (Loaded)	6
Circuits (maximum)	6
Color - Resin	Black
Durability (mating cycles max)	25
Flammability	94V-0
Glow-Wire Capable	No
Material - Metal	Phosphor Bronze
Material - Plating Mating	Tin
Material - Plating Termination	Tin
Material - Resin	High Temperature Thermoplastic
Net Weight	1.410/g
Number of Rows	1
Orientation	Vertical
PCB Thickness - Recommended	1.57mm
Packaging Type	Embossed Tape on Reel
Pitch - Mating Interface	2.54mm
Plating min - Mating	3.810µm
Plating min - Termination	3.810µm
Polarized to Mating Part	Yes
Shrouded	Fully
Surface Mount Compatible (SMC)	Yes
Temperature Range - Operating	-40° to +105°C
Termination Interface: Style	Surface Mount

Electrical

Current - Maximum per Contact	3.0A
Voltage - Maximum	250V

Solder Process Data

Duration at Max. Process Temperature (seconds)	040
Lead-free Process Capability	REFLOW
Max. Cycles at Max. Process Temperature	003

EU ELV

Not Relevant

EU RoHS

Compliant

REACH SVHC

Not Contained Per -
ED/61/2018 (27 June
2018)

Halogen-Free

Status

Not Low-Halogen

For more information, please visit [Contact US](#)

China ROHS

ELV

RoHS Phthalates

China RoHS

Green Image

Not Relevant

Not Contained

Search Parts in this Series

[74099](#) Series

Mates With

SL Crimp Housing [70400](#) Option G, [70430](#)
Option G, [70066](#) Option G

Use With

SL Crimp Terminals [70058](#) , [71851](#)

Process Temperature max. C

245

Material Info

Reference - Drawing Numbers

Packaging Specification

PK-70873-9000

Product Specification

PS-70400-001, PS-70541-001, TS-70541-001-001,

TS-70541-100-001

Sales Drawing

SD-74099-1000

This document was generated on 11/26/2018

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION