

BRIGHT

- 3 white LEDs deliver up to 30 lumens in high mode



VERSATILE

- 3 light modes
- High and low white mode for general illumination
- Red mode to help preserve night vision



DURABLE

- Passes 2-meter drop test
- LEDs are virtually unbreakable



WEATHERPROOF

- Meets IEC 60529 IPX4 standards
- Continues to operate after exposure to splashing water from all directions



CAPR22E

Ideal for situations that call for hands-free lighting, the Energizer® Performance LED Cap Light attaches easily and securely to a cap brim. The 90° pivot range allows you to direct the light where it's needed. And since the light mounts on top of the brim, it won't obstruct your vision. Variable light sources allow you to choose the best illumination for the job – high or low white, or red to preserve your night vision.




Before Using Your Flashlight:
Please read all instructions and cautionary markings on the package and light

Product Detail:

- Designation:** Energizer Performance LED Cap Light
- Model:** CAPR22E
- Color:** Red and Black
- Power Source:** Two "AAA"
- ANSI/NEDA:** Series 24
- Lamp:** 3 White LEDs, 2 Red LEDs
- Lamp Life (hr):** Lifetime
- Lamp Output (lumens):** High - 30, Low - 15, Red - 2
- Beam Distance (m):** High - 20, Low - 14
- Peak Beam Intensity (cd):** High - 100, Low - 42
- Run Time (h:mm):** Alkaline High - 3, Low - 9
Lithium High - 6, Low - 14
- Typical Weight:** 87 grams
with 2 alkaline AAA batteries
- Dimensions (mm):** 22 x 74 x 53

Performance:

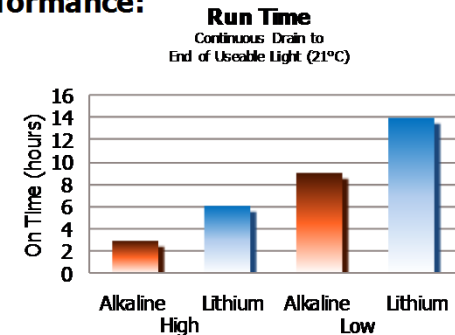

Tested according to ANSI/NEMA FL 1 Standards.

Important Notice

This datasheet contains information specific to products manufactured at the time of its publication
Contents herein do not constitute a warranty
©Energizer / All Rights Reserved