

# SIEMENS

## Product data sheet

## 3RT1016-1AF01



Abb. ähnlich / similar picture

CONTACTOR, AC-3 4 KW/400 V, 1 NO,  
AC 110 V, 50/60 HZ, 3-POLE, SIZE S00,  
SCREW CONNECTION

### General details:

Size of the contactor	S00
Number of poles	3

### Control circuit:


Design of activation of the operating mechanism	conventional
Type of voltage	AC
Control supply voltage	
• at 50 Hz / for AC / rated value / minimum	110 V
• at 50 Hz / for AC / rated value / maximum	110 V
• at 60 Hz / for AC / rated value / minimum	110 V
• at 60 Hz / for AC / rated value / maximum	110 V

Supply voltage frequency / for auxiliary and control current circuit / rated value	
• minimum	50 Hz
• maximum	60 Hz

### Main circuit:

Number of NC contacts / for main contacts	0
Number of NO contacts / for main contacts	3
Operating current	

• at AC-3 / at 400 V / rated value	9 A
• at AC-1 / at 400 V / rated value	22 A
Service power	
• at AC-3 / at 400 V / rated value	4 kW
• at AC-1 / at 400 V / rated value	13 kW
<b>Auxiliary circuit:</b>	
Identification number and letter for switching elements	10 E
Number of NO contacts / for auxiliary contact	1
Number of NC contacts / for auxiliary contact	0
<b>Connection type:</b>	
Design of the electrical connection / for main current circuit	screw-type terminals
Design of the electrical connection / for auxiliary and control current circuit	screw-type terminals
<b>Mounting/fixing:</b>	
Type of fixing/fixation	screw and snap-on mounting onto 35 mm standard mounting rail according to DIN EN 50022
Series installation	Yes

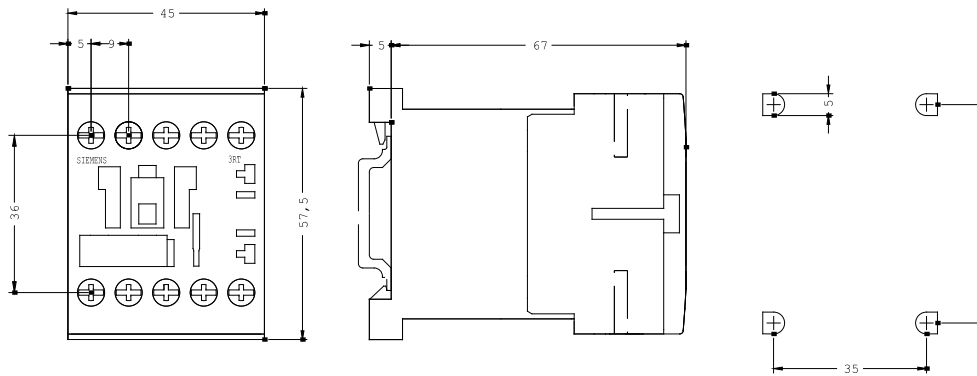

last change:

10/31/2006

<b>Technical Assistance:</b>	Telephone:	+49 (0) 911-895-5900 (8 <sup>00</sup> - 17 <sup>00</sup> CET)
	Fax:	+49 (0) 911-895-5907
	E-Mail:	<a href="mailto:technical-assistance@siemens.com">technical-assistance@siemens.com</a>
	Internet:	<a href="http://www.siemens.de/lowvoltage/technical-assistance">www.siemens.de/lowvoltage/technical-assistance</a>