

SIEMENS

Product data sheet

3RU1116-1FB0



Abb. ähnlich / similar picture

OVERLOAD RELAY, 3.5...5 A, 1NO+1NC,
SIZE S00, CLASS 10,
FOR CONTACTOR MOUNTING


General technical details:

Operating current / of the fuse link / rated value	20 A
Adjustable response current / of the current-dependent overload release / initial value	3.5 A
Adjustable response current / of the current-dependent overload release / final value	5 A
Service power / for three-phase servomotors / rated value	1.5 kW
Number of NC contacts / for auxiliary contact	1
Number of NO contacts / for auxiliary contact	1
Number of change-over switches / for auxiliary contact	0
Type of assignment	2
Type of protection	DMT 98 ATEX G 001

Mechanical design:

Design of the electrical connection / for main current circuit	screw-type terminals
Design of the electrical connection / for auxiliary and control current circuit	screw-type terminals
Size of the contactor / can be combined / company-specific	S00

Type of fixing/fixation	direct mounting
Size of overload relay	S00
Ambient conditions:	
Protection class IP	IP20

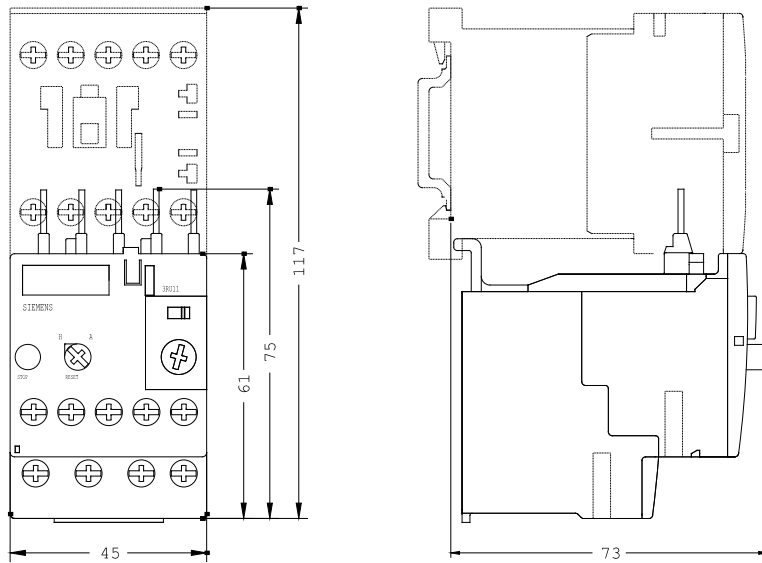

last change:

10/31/2006

Technical Assistance:	Telephone:	+49 (0) 911-895-5900 (8°° - 17°° CET)
	Fax:	+49 (0) 911-895-5907
	E-Mail:	technical-assistance@siemens.com
	Internet:	www.siemens.de/lowvoltage/technical-assistance