



MOULDED-PLASTIC ENCLOSURE FOR WALL MOUNTING
 DEGREE OF PROTECTION IP55,
 WITH N AND PE TERMINAL LOCKABLE IN 0 POSITION
 72MM

Certificates/ approvals:

General Product Approval



Declaration of Conformity



Test Certificates

[Special Test Certificate](#)

[Type Test Certificates/Test Report](#)

Shipping Approval



ABS



BUREAU VERITAS



RMRS

other

[Confirmation](#)

[Declaration of Conformity](#)

[other](#)

[Environmental Confirmations](#)

Further information:

Information- and Downloadcenter (Catalogs, Brochures,...)



<http://www.siemens.com/industrial-controls/catalogs>

Industry Mall (Online ordering system)

<http://www.siemens.com/industrial-controls/mall>

Cax online generator

<http://www.siemens.com/cax>

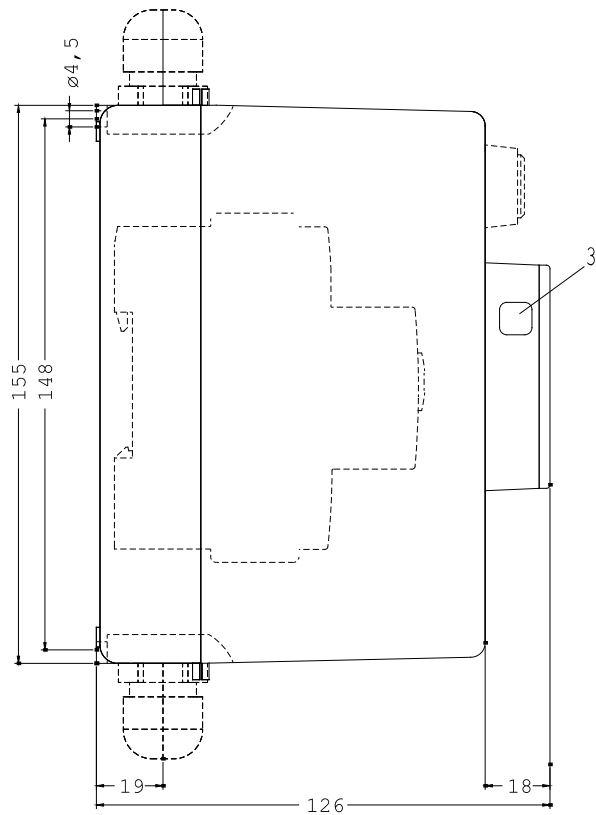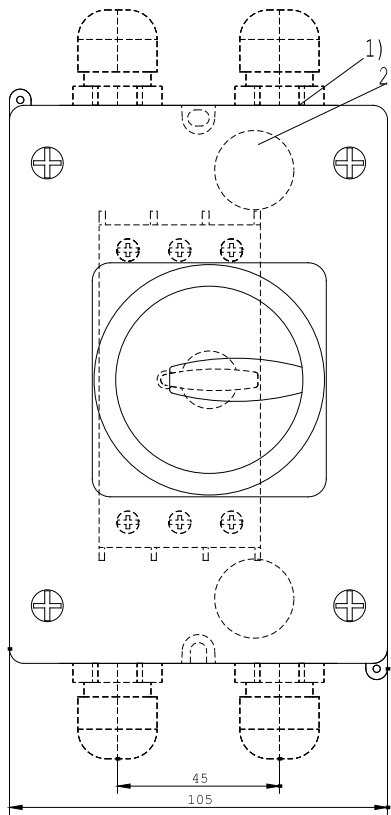

schneidöffnung fuer Verschraubung M25
öffnungsweite fuer ruckseitige Leitungseinfuehrung
max. 8 mm
Vorhaenges Schloss mit Buegeldurchmesser max. 8 mm

last change: