



ENCLOSURE FOR 22MM PROGRAM METAL VERSION 4
COMMAND POSITIONS GRAY TOP PART

Enclosure:

Design of the enclosure		Empty enclosure for command and signaling devices
Material / of the enclosure		metal
Color / of top part of the enclosure		grey
Number of Command Points		4
Product component / protective collar		No
Form / of the enclosure front		rectangular
Design of electrical connection / on enclosure		Cable routing above, below / left, right, each 1 x M25
Type of mounting / of enclosure		Vertical / horizontal
Product function / EMERGENCY STOP function		No

Actuator / signaling device:

Product component / front ring		No
---------------------------------------	--	----

Contact block / lampholder

Product function / positive opening		No
Type of fixing/fixation / for contact blocks		Floor mounting / front mounting (1-pole)
Product component / fluorescent materials		No
Product extension / optional / fluorescent materials		Yes

Accessories:

Number of labeling plates		4
Product component / holder for 3 switching elements		No

General technical details:

Delivery state / pre-wired on strip terminal		No
Product component / stand/pedestal		No
Resistance against shock <ul style="list-style-type: none"> • for devices with incandescent lamp / according to IEC 60068-2-27 • for devices without incandescent lamp / according to IEC 60068-2-27 		<= 30g <= 50g
Resistance against vibration / according to IEC 60068-2-6		20 ... 200 Hz: 5g
Item designation <ul style="list-style-type: none"> • according to DIN EN 61346-2 • according to DIN 40719 extendable after IEC 204-2 / according to IEC 750 		U S
Ambient temperature <ul style="list-style-type: none"> • during operating • during storage 	°C °C	-25 ... +70 -40 ... +80
Protection class IP		IP67
climatic class / during the operating phase / according to EN 60721		3K6
Shape / of the installation hole		round
Mounting diameter	mm	22
Width	mm	85
Height	mm	194
Depth	mm	65

Certificates/approvals:

General Product Approval	Declaration of Conformity	Test Certificates	Shipping Approval
 CSA  GOST  UL	 EG-Konf.	Special Test Certificate	 DNV

other

[Confirmation](#)

[Environmental Confirmations](#)

Further information:

Information- and Downloadcenter (Catalogs, Brochures,...)

<http://www.siemens.com/industrial-controls/catalogs>

Industry Mall (Online ordering system)

<http://www.siemens.com/industrial-controls/mall>

Cax online generator:


<http://www.siemens.com/cax>

Service&Support (Manuals, Certificates, Characteristics, FAQs,...)

<http://support.automation.siemens.com/WW/view/en/3SB3804-2AA3/all>

Image database (product images, 2D dimension drawings, 3D models, device circuit diagrams, ...)

http://www.automation.siemens.com/bilddb/cax_en.aspx?mlfb=3SB3804-2AA3

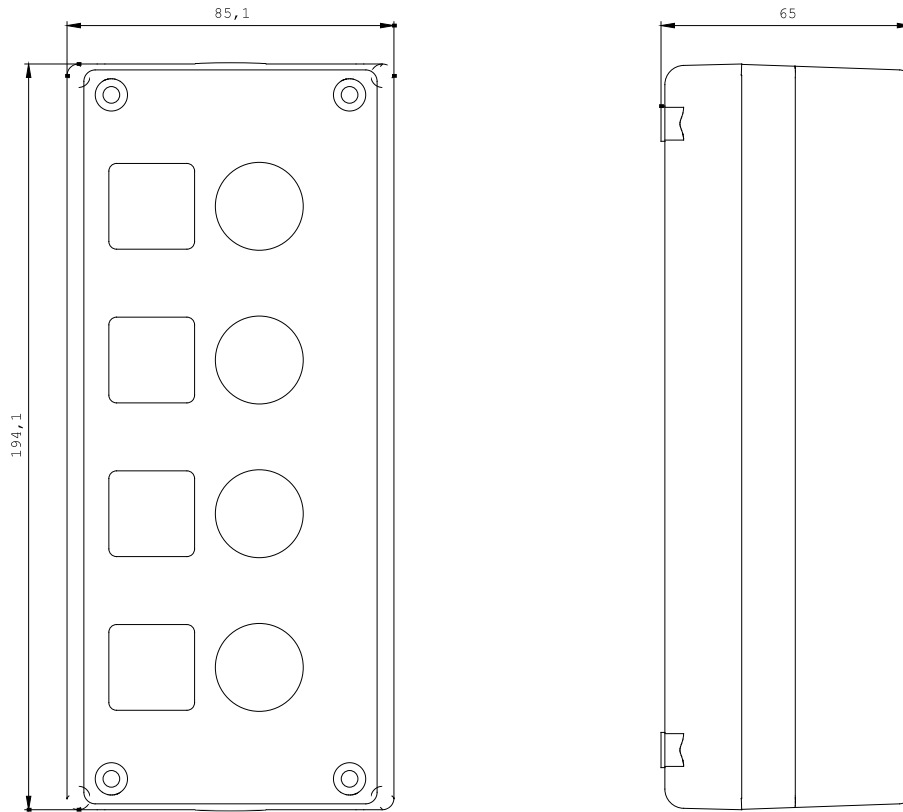

\R9.4+
\R9.1;

last change:

Feb 8, 2013