


BCC M434-0000-2A-000-43X434-000  
BCC08C0

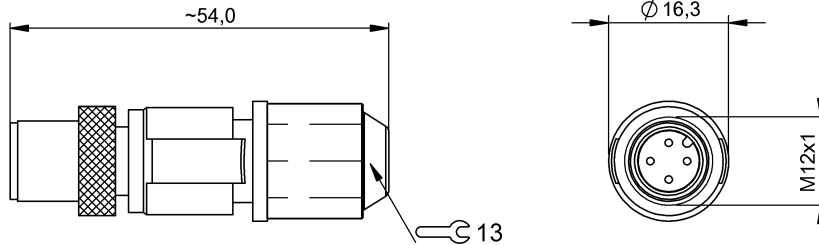

## Display/Operation

Power indicator no

## Electrical connection

Cable diameter D 3.5...6 mm  
Number of pins 4  
System Can be fabricated

## Electrical data

Rated current (40 °C) 4.0 A

## Environmental conditions

Ambient temperature -25...80 °C  
Protection type IEC 60529 IP67

## Material

Material contacts Bronze  
Material cover nut Die-cast zinc  
Material grip PA


## Mechanical data

Connection cross-section 0.14...0.34 mm<sup>2</sup>  
Type of wire mounting Insulation displacement connector technology

## Remarks

Enclosure rating per IEC 60529, only in screwed state with the associated mating piece.

## Connector view

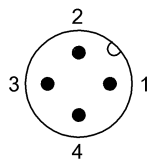

PIN 1-4 usable