


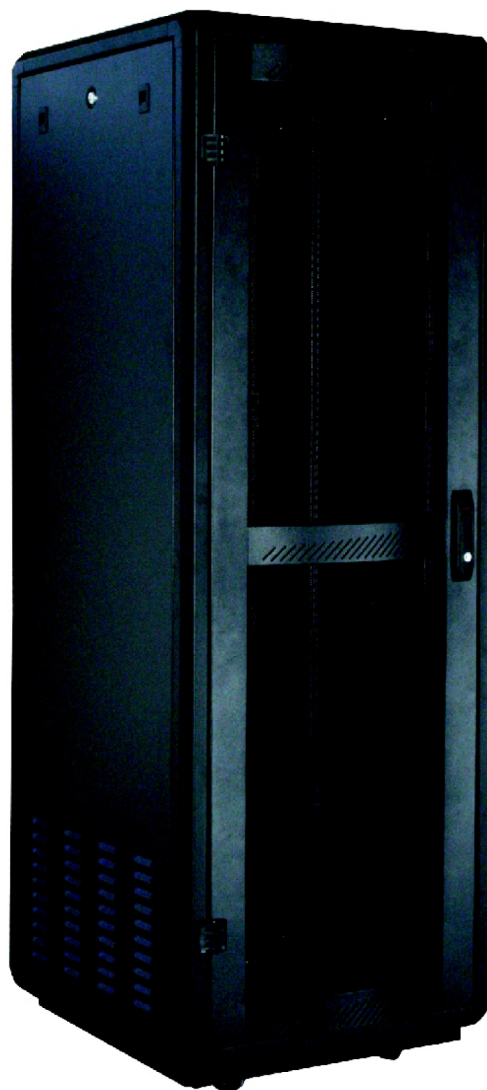

Features:

- ▶ Mesh front door design for airflow and heat dissipation.
- ▶ Vented on all panels for excellent air circulation characteristics.
- ▶ Top panel features cutouts for fans and cutouts for cable access. Platform features cutouts for cable access.
- ▶ Features 6 fully adjustable internal equipment cage nut rails for #12-24 mounting screws in EIA universal spacing.
- ▶ Comes packaged complete with front door, rear and side panels, leveling feet, casters, grounding bus bar, 2 pre-installed 80 CFM fans and equipment screws.
- ▶ Reversible front door.
- ▶ Each enclosure supplied with cage nut hardware set.
- ▶ Meets or exceeds EIA 310D standards.
- ▶ Electrostatic microfinish paint.
- ▶ Ships fully assembled.



Specifications					AWG					
Stock No.	Height	Format	RU	Color	Structure	Side Panels	Top Panel	Rear Panel	Front Door	Base
FE7419-40-01	6'	19"	40 RU	Ivory	16	16	16	16	16	14
FE7419-40-02	6'	19"	40 RU	Black	16	16	16	16	16	14
FE7419-45-01	7'	19"	45 RU	Ivory	16	16	16	16	16	14
FE7419-45-02	7'	19"	45 RU	Black	16	16	16	16	16	14

RU = Rack Units