


Product Datasheet

[Catalog Home](#)[Home Page](#)[Search](#)

DRUBKIT -- Straight Blade Products, DIN Rail Utility Box

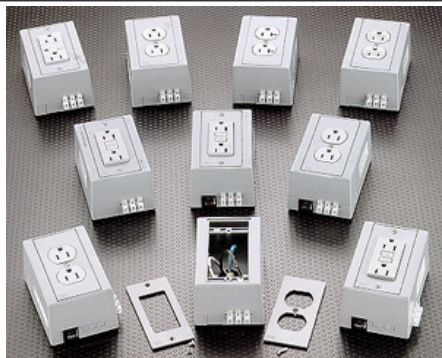


DRUB Unit- Kit Form

Product Specifications

Product Type


DIN Rail Utility Box

DIN Rail Utility Box Variety	Kit less Receptacle
With Circuit Breaker?	No
Amperage	15A
Voltage	125V
Poles and Wires	2 Pole, 3-Wire Grounding
NEMA No.	None
Certification	UL Recognized and CSA Certified
Box Terminals Material	Brass
Dielectric Voltage	Withstands 2,000V minimum.
Current Interrupting	Certified for current interrupting at full rated current.
Temperature Rise	Max 30°C temperature rise at full rated current after 50 cycles of overload at 150% of rated current at a power factor of 75%..
Terminal Identification	Terminals identified in accordance with UL498 (Brass, White, Green).
Terminal Accommodation	#14-#12 AWG copper stranded or solid conductor only.
Product Identification	Ratings are a permanent part of the device.
UPC Number	783585108124
Weight in LBs	0.650
Link to Drawing Library	Click here for Library
Link to PDF Catalog	Click here for Catalog

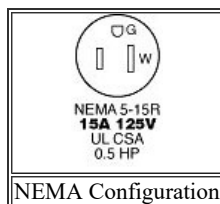

NEMA Configuration

