

 
Midget Twist-Lock® Devices
 15A, 125V, 2 Pole, 2 Wire Non-Grounding
 Valise® Plug

HUBBELL



Features

- Fully insulated, abuse resistant nylon housing
- Insulation displacement terminals reduce wiring time
- Insulation displacement terminal
- Powerful, cord-gripping jaws
- Totally insulated body adds extra measure of safety



15A 125V
 NEMA ML-1R



Ordering Information


Description	Cord Diameter	UPC	Catalog Number
Black Valise® plug.	.220"-.385" (5.6-9.8)	783585237282	HBL7465V

Listings

Listed to UL 498
 Certified to CSA C22.2 No.42
 Fed Spec W-C-596

Specifications

Housing	Nylon
Blades	Brass
Terminal Screws	#6 - 32 Steel (Philips / Slotted / Robertson)
Terminal Clamps	Steel - Nickel plated
Body Holding Screws	Steel - Zinc plated

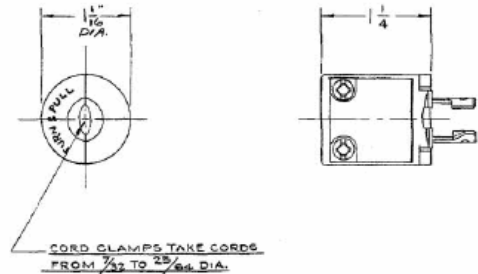

Performance

Electrical

Current Interrupting	Certified for current interrupting at full rated current
Dielectric Voltage	Withstands 2,000V minimum

Mechanical

Terminal Accomodation	#18 AWG - #14 AWG stranded copper wire only.
Terminal Identification	Terminals identified in accordance with UL 498

Environmental

Flammability	HB or better per UL94/CSA 22.2 No.0.17
Moisture Resistance	IP20 Suitability
Operating Temperatures	Maximum Continuous 75°C Minimum -40°C (w/o impact)

Accessories

Valise® Connector	HBL7464V
Flanged Receptacle	HBL7468
Weatherproof Boot	HBL7490V

Resources

Customer Use Drawing
 eCatalog

Dimensions in Inches (mm)

Hubbell Wiring Device-Kellems • Hubbell Incorporated (Delaware) • 40 Waterview Drive • Shelton, CT 06484

Phone (800) 288-6000 • Fax (800) 255-1031 • Specifications subject to change without notice.

