

# PANEL MOUNT INDICATOR, NON-RELAMPABLE

## LED TECHNOLOGY

MOUNTING HOLE, Ø 0.310"

PART NO.	LENS COLOR	VOLTAGE	CURRENT [mA]	RATED LIFE HOURS
<b>LED 6V SERIES</b>				
WL-2191L1-6V	RED	5V-6V	20mA	100,000
WL-2191L5-6V	GREEN	5V-6V	20mA	100,000
WL-2191L7-6V	YELLOW	5V-6V	20mA	100,000
<b>LED 12V SERIES</b>				
WL-2191L1-12V	RED	12V-14V	20mA	100,000
WL-2191L5-12V	GREEN	12V-14V	20mA	100,000
WL-2191L7-12V	YELLOW	12V-14V	20mA	100,000
<b>LED 24V SERIES</b>				
WL-2191L1-24V	RED	24V-28V	20mA	100,000
WL-2191L5-24V	GREEN	24V-28V	20mA	100,000
WL-2191L7-24V	YELLOW	24V-28V	20mA	100,000

## NOTES

1. Minimum panel thickness 0.030"
2. 6" leads with 1/2" strip are standard
3. Storage temperature  
T<sub>STG</sub>: -25°C - +80°C
4. Ambient temperature  
T<sub>A</sub>: -20°C - +60°C
5. Voltage tolerance  
V<sub>OP</sub>: ±10%
6. Body material  
Nylon, white
7. Lens material  
Polycarbonate
8. Bezel material  
Chrome
9. Wire gauge  
18 AWG
10. Wire strip  
1/2"
11. Anode(+)  
Red lead


## CERTIFICATIONS

UL (E340667), RoHS



**RoHS**  
COMPLIANT

## DIMENSIONAL CHARACTERISTICS

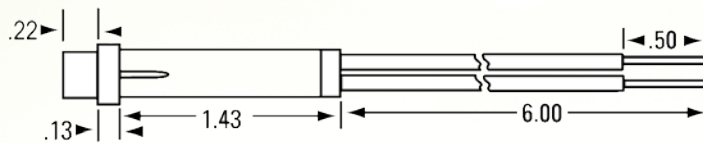

unless otherwise specified, all dimensions are in inches



## OPTIONS

Additional options and lens styles available. Please contact Wamco for more information.

