

# Electronics cases - Interscale M

## Desktop cases




- Modular desktop case consisting of 4 assembled parts
- Case available in two versions: Plain or perforated for forced cooling with fans
- Ingress protection IP 30 (plain version)
- Color RAL 7016

**NEW**

### Delivery includes (assembled)

Item	Qty	Description
1	1	Base with 2 side panels (plain or perforated), St, 1 mm, AlZn coated, RAL 7016 (anthracite gray)
2	1	Top cover, St, 1 mm, AlZn coated, RAL 7016
3	1	Front panel, Al, 1 mm, RAL 7016
4	1	Rear panel, Al, 1 mm, RAL 7016
5	1	Assembly kit and user manual

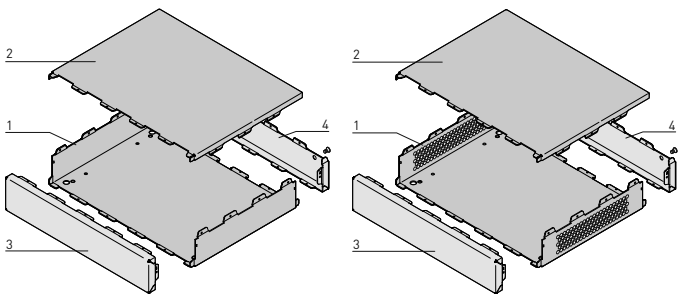

Plain case

Perforated case



ServicePLUS see page 8.112

### Order Information

Height	Width	Depth	Desktop case plain	Desktop case, perforated			Mounting plate	PCB support for mounting plate
				Desktop case perforated	Mounting plate with built-in fan	Fan holder with fans		
U	mm	mm	mm	Part no.	Page 5.124	Page 5.125	Page 5.126	Page 5.126
1	44	133	133	14820-133	-	-	24822-033	24827-023
1	44	133	177	14820-134	-	-	24822-034	24827-024
1	44	221	177	14820-154	14825-154	24827-154	24828-104	24827-024
1	44	221	221	14820-155	14825-155	24827-155	24828-105	24827-025
1	44	310	221	14820-175	14825-175	24827-175	24828-105	24827-025
1	44	399	221	14820-195	14825-195	24827-195	24828-105	24827-025
1	44	399	310	14820-197	14825-197	24827-197	24828-107	24827-027
2	88	221	177	14820-254	14825-254	24827-254	24828-204	24827-024
2	88	221	221	14820-255	14825-255	24827-255	24828-205	24827-025
2	88	310	221	14820-275	14825-275	24827-275	24828-205	24827-025
2	88	399	221	14820-295	14825-295	24827-295	24828-205	24827-025
2	88	399	310	14820-297	14825-297	24827-297	24828-207	24827-027
3	133	310	221	14820-375	14825-375	24827-375	24828-305	24827-025
3	133	399	221	14820-395	14825-395	24827-395	24828-305	24827-025
3	133	399	310	14820-397	14825-397	24827-397	24828-307	24827-027

### Accessories

Clip for horizontal rail mounting PU 2 pieces	24820-002
Adhesive base Height 5 mm, PU 10 pieces (adhesive base, screw, washer)	24827-005
Adhesive base Height 7 mm, PU 10 pieces (adhesive base, screw, washer)	24827-007
Adhesive base Height 9 mm, PU 10 pieces (adhesive base, screw, washer)	24827-009
Assembly tool plastic, with Torx T10 bit, 1 kit	24820-001
Plastic tip-up foot anthracite, similar to RAL 7016, 4 pieces	20603-002
Stacking aid anthracite, similar to RAL 7016, PA, UL 94 V-0, PU 4 pieces	20603-003
Plastic foot PC, UL 94 V-0, for material thickness 1 ... 3, 1 piece (SPQ 50)	60224-009

### Note

- Modified or customized cases on request