


FLAT NOSE PLIER

P10


 
- Precision nose plier with serrated jaws
- Jaw width 3mm
- Length 140mm

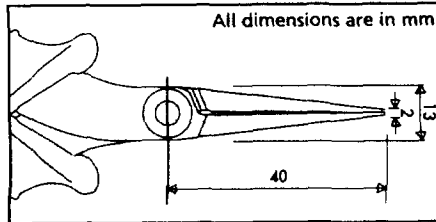

LONG NEEDLE NOSE PLIER

P11



- Long-needle nose plier with serrated jaws
- Tapered jaw to 1.2mm width
- Length 152mm

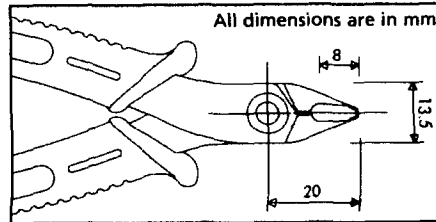

FLUSH CUTTER

P13



- Max wire \varnothing 16 AWG/.051" (1.3mm) soft wire
- Cutting angle 21°
- Length 132mm
- Safety clip available. Add "-A" to Part No.

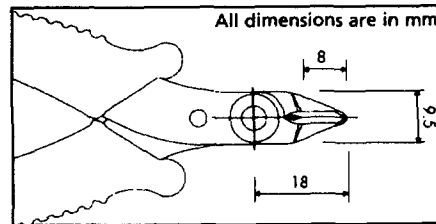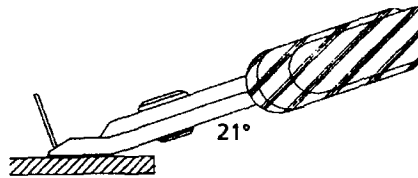

LIGHTWEIGHT FLUSH CUTTER

P13-LW



- Max wire \varnothing 16 AWG/.051" (1.3mm) soft wire
- Cutting angle 21°
- Lightweight 1.6oz (45g)
- Length 125mm
- Safety clip available. Add "-A" to Part No.

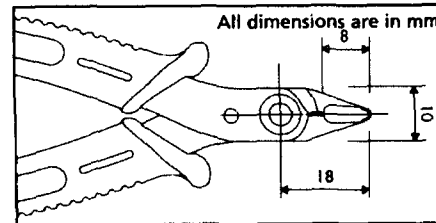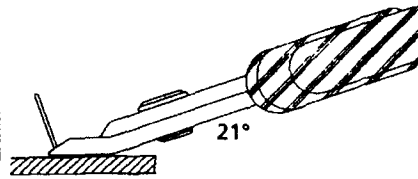

ANGLED FLUSH CUTTER

P14



- Max wire \varnothing 16 AWG/.051" (1.3mm) soft wire
- Cutting angle 21°
- Length 130mm
- Safety clip available. Add "-A" to Part No.

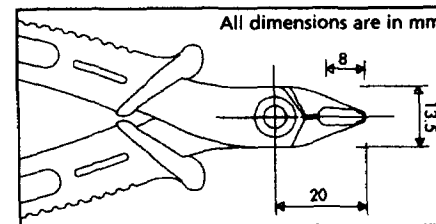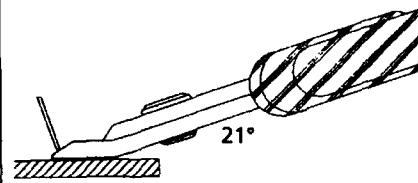

FLUSH CUTTER

P15



- Max wire \varnothing 16AWG/.051" (1.3mm)
- Cutting angle 48°
- Length 130mm

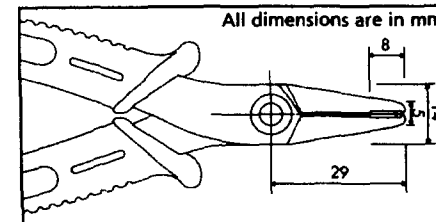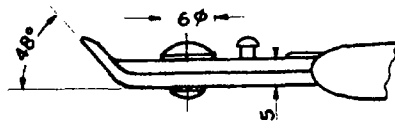

ANGLED HEAD CUTTER

P17



- Max wire \varnothing 18 AWG/.040" (1.0mm)
- Cutting angle 30°
- Length 140mm

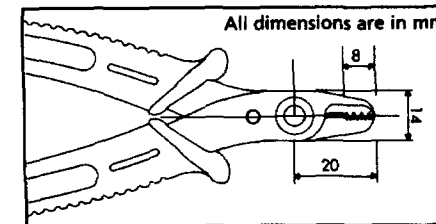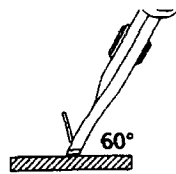

WIRE STRIPPER

P21

- Max wire \varnothing 28-24 AWG/.012"-.020" (0.3-0.5mm)
- Length 132mm

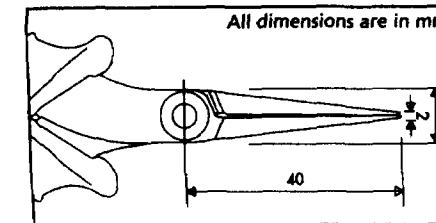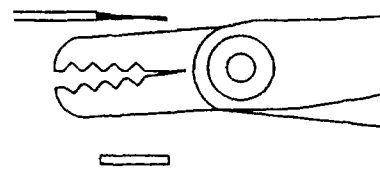

LONG FLAT NOSE PLIER

P24

- Long flat nose plier with serrated jaws.
- Jaw width 3mm
- Length 152mm

