




ENGLISH

Datasheet RS Pro Shaft Vice

RS Stock No: 463-7303

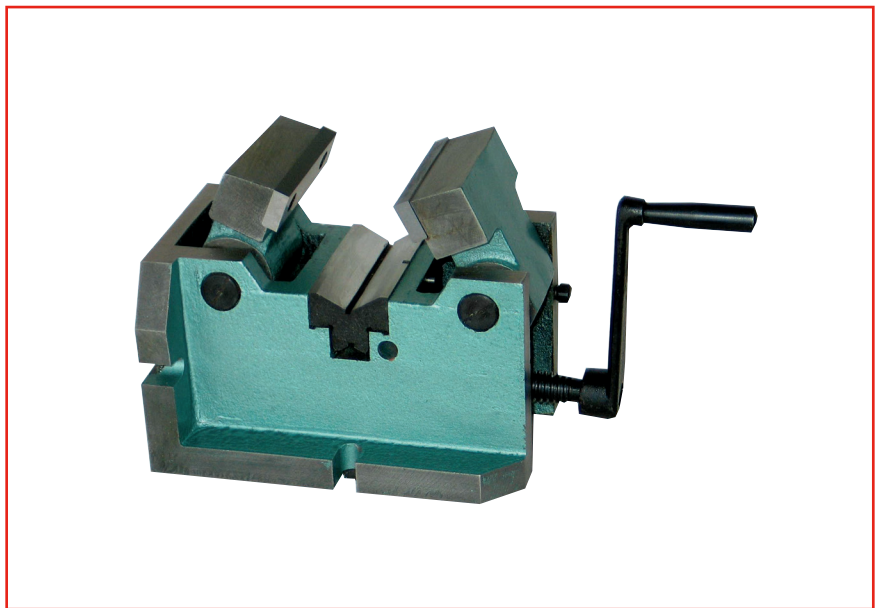

Specifications:

Suitable for gripping shafts & pipes 10mm - 80mm

Precision ground, parallelism to 0.0008"

Parallelism of sliding surface to base 0.0005"

Reversible centre vee blocks for small diameter pipes & shafts

Jaw Width: 100mm

Jaw Height: 35mm

Jaw Opening: 10-80mm

Order Code	Manufacturers Code	Description
463-7303	52-485-100	Shaft Vice



ENGLISH

Datasheet

RS Pro Shaft Vice

General Specifications:

Diameter Clamping Range mm	Jaw Width mm	Locating Key Width mm	Clamping Bolt Size mm	Overall Dimensions L x W x H mm	Weight Kg
10 - 80	100	14	M12	296 x 163 x 155	19

Accuracy Specifications:

Parallelism of Vee to Base mm	Squareness between 90° Base Faces mm	Centrality of Vee to Clamping Jaws mm	Squareness of Locating Keys to Vee mm
0.05 over 100mm	0.05 over 100mm	0.05	0.05 over 100mm