


Professionally approved products.

Datasheet

135mm Chrome Molybdenum Steel Circlip Pliers with Straight Tip, External, Range 3 to 10mm

RS Stock number [541-6826](#)

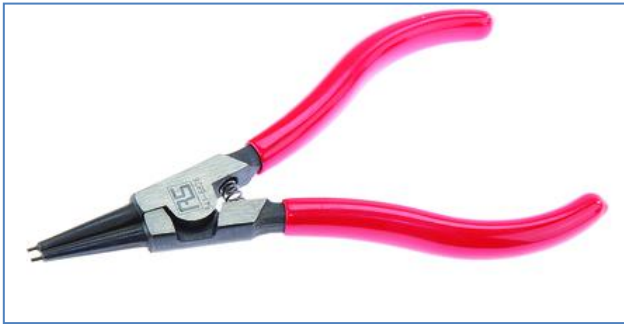

Specification:

- Material: Chrome molybdenum steel (63cr-mo) for pliers, spring steel for automatic return function and vinyl dipping handles.
- Finish: Chemical black finish with polish main surface for pliers, red colour handle
- Hardness: Heat treated to HRC: 45 ~ 55 (circlip tip), HRC: 44 ~ 48 (handle) and HRC: 30 ~ 48 (joint)

Contents:

1 pc-5" (135 mm) external straight type, small cylindrical tip circlip plier with automatic return spring and red colour vinyl dipping grip (diameter of tip - 0.9mm, overall length-135 mm, jaw length-32.0 mm, thickness of joint-8.0 mm, circlip seal ring capacity - 3~10 mm, weight - 90 grams)

Remarks:

Dimensions, handle spin, retaining tests, permanent and humidity meet din-5254 standard. (form a type)