

Point-of-Purchase packaging provides convenient solutions for control, signaling, and relay products.

Need to grab and go? Visit your local Schneider Electric distributor today to grab the right products conveniently packaged together with all the selection and accessories you need. Point-of-Purchase packaging does all the thinking for you so that you can just grab what you need – and go!

30 mm products

Features and benefits

- Heavy-duty pushbuttons, selector switches, and pilot lights for industrial applications
- Oiltight, watertight, and dustproof (rated for NEMA® Types 4 and 13 environments without boots)
- Includes multiple color inserts or legend plates (where applicable) — use what you need, discard what you don't
- Fingersafe® terminals for improved safety
- UL® listed, CSA® approved, CE per IEC®



30 mm pushbuttons



30 mm pilot light



30 mm control station

30 mm pushbuttons

Description	POP Catalog Number	Package Includes
30 mm pushbutton with contact block and multi colors	9001AB1	9001KR1U + KA1 + KN201 + KN202
30 mm push/pull mushroom	9001AB2	9001KR9R + 9001KA1
30 mm mushroom with legend	9001AB3	9001KR5R + KA1 + KN205
30 mm two-position selector switch with contact and legend	9001AS1	9001KS11B + 9001KA1 + 9001KN244
30 mm three-position selector switch with contact and legend	9001AS2	9001KS43B + 9001KA1 + 9001KN260

Pilot light

Description	POP Catalog Number	Package Includes
Pilot light (KP)	9001AL1	9001KP1 + 9001R9 + 9001G9

30 mm control station

Description	POP Catalog Number	Package Includes
30 mm control station	9001AE3	9001BG201

BW pendant station

Features and benefits


- Easy to hold in one hand with contoured grip
- Single- or two-speed buttons
- Momentary or maintained contact
- Available with or without mechanical interlocks
- Yellow, black, or red enclosure options
- High-impact thermoplastic enclosure with self-extinguishing flammability rating (UL 94V)
- Oiltight, watertight, dustproof, and corrosion-resistant (rated for NEMA 1, 3, 3R, 4, 4X, and 13)
- UL listed, CSA certified, CE per IEC

Description	POP Catalog Number	Package Includes
BW pendant	9001BWP1	9001BW92Y



BW pendant

Make the most of your energySM

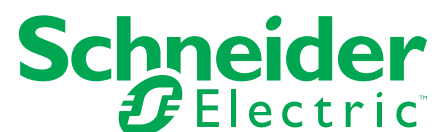

22 mm pushbuttons.....

Features and benefits

- Simple, flexible, and robust pushbuttons, selector switches, control stations, and pilot lights for industrial applications
- Ideal for applications exposed to high-pressure cleaning, dust, and extreme temperatures
- Easy, secure mounting with a snap-fit head and body, tightened with a single screw
- UL Listed, CSA Approved, CE per IEC
- Rated for NEMA 1, 3, 3R, 4, 12, 13

Description	POP Catalog Number	Package Includes
22 mm pushbutton w/contact + six colors	XB4AB1	ZB4BZ101 + ZB4BA9
22 mm mushroom w/NC contact	XB4AB2	XB4BS542
22 mm two-position selector switch w/NO contact	XB4AS1	XB4BD21
22 mm three-position selector switch w/two NO contacts	XB4AS2	XB4BJ33
22 mm control station — mushroom w/NC contact	XALACS1	XALK178H7
22 mm control station — two button (start/stop) w/NO, NC contact	XALACS2	XALD211H29H7



22 mm pushbutton with contact block



22 mm mushroom button with contact block



22 mm 2-position selector switch



22 mm 3-position selector switch



22 mm mushroom control station



22 mm 2 button control station

40 mm tower light.....

Features and benefits

- Up to five illuminated signaling units
- Steady light or flashing Super Bright LEDs
- Available in red, orange, green, blue, or clear
- Available with or without an audible buzzer (up to 85 decibels)
- Three screws for base mounting or aluminum support tube with a bracket
- UL recognized, CSA approved, CE per IEC

Description	POP Catalog Number	Package Includes
40 mm tower light (3) 24 VAC/VDC	XVCTL1	XVC4B3K



40 mm tower light

Open style power relay.....

Features and benefits

- Open frame power relay
- High-power contacts
 - » Up to 40 A switching
 - » Up to 2 HP motor load rating
- Riveted construction
- RoHS compliant
- UL Listed, CSA Approved, CE per IEC

Description	POP Catalog Number	Package Includes
40 A DPDT power relay, 120 VAC coil	8501CDPDT	8501CO16V20
40 A DPST power relay, 120 VAC coil	8501CDPST	8501CO7V20
40 A SPST power relay, 120 VAC coil	8501CSPST	8501CO6V20



40 A DPDT



40 A DPST



40 A SPST

Slim interface relays, RSL and RSB

Features and benefits

- An offer with maximum flexibility, comprising complete products and a single reference for a relay mounted on a socket
- Choice of sockets covering a range of voltages from 12 V to 230 V
- Conforms to international standards IEC/EN 61810-1, UL-508, CSA C22.2 N°14, GOST

Description	POP Catalog Number	Package Includes
SPDT slim relay and socket, screw terminal, 24 VAC/VDC coil	ASLSCR24	RSL1PVBU + RSLZ5
SPDT slim relay and socket, spring terminal, 24 VAC/VDC coil	ASLSPR24	RSL1PRBU + RSLZ5
SPDT slim relay and socket, screw terminal, 120 VAC/VDC coil	ASLSCR120	RSL1PVFU + RSLZ5
SPDT slim relay and socket, spring terminal, 120 VAC/VDC coil	ASLSPR120	RSL1PRFU + RSLZ5
SPDT PCB plug-in relay and socket, 24 VDC coil	RSB1SOC24D	RSB1A120BD + RSE1S35M + RZM031RB + RSZR215 + RSZL300
DPDT PCB plug-in relay and socket, 24 VDC coil	RSB2SOC24D	RSB2A080BD + RSE1S48M + RZM031RB + RSZR215 + RSZL300



SPDT slim relay & socket, screw 24 V



SPDT slim relay & socket, spring 24 V



SPDT slim relay & socket, screw 120 V



SPDT slim relay & socket, spring 120 V



SPDT PCB plug-in relay & socket 24 VDC



DPDT PCB plug-in relay & socket 24 VDC

Plug-in style power relays, RPM and RXM

Features and benefits

- General-purpose relay
- 15 A switching capacity
- Up to 1 hp motor load rating
- Complete system solution
 - » Relay, socket, protection module
 - » Ejector clip, ID tag
- RoHS compliant
- UL Listed, CSA Approved, CE per IEC

Description	POP Catalog Number	Package Includes
SPDT power plug-in relay and socket, 24 VDC coil	RPM1SOC24D	RPM12BD + RPZF1 + RPZR235 + RXM040W + RXZL520
SPDT power plug-in relay and socket, 120 VAC coil	RPM1SOC120A	RPM12F7 + RPZF1 + RPZR235 + RXM021FP + RXZL520
4PDT control plug-in relay and socket, 24 VDC coil	RXM4SOC24D	RXM4AB2BD + RXZE2M114 + RXM040W + RXZR335 + RXZL520
4PDT control plug-in relay and socket, 120 VAC coil	RXM4SOC120A	RXM4AB2F7 + RXZE2M114 + RXM021FP + RXZR335 + RXZL520



SPDT POWER plug-in relay & socket, 24 VDC



SPDT POWER plug-in relay & socket, 120 VAC



4PDT control plug-in & socket, 24 VDC



4PDT control plug-in & socket, 120 VAC

Solid state relays

Features and benefits

- Fingersafe — protects operators from live circuits
- Green LED — indicates line power
- Back-to-back SCRs — improves reliability when switching inductive loads
- Direct copper bonded (DCB) — enhances heat transfer for more efficient dissipation
- Internal snubber — protects relay against transients damaging internal circuitry for greater reliability
- Riveted base plate — increases safety in the event of a short circuit
- UL listed (DIN mount), UL recognized (panel mount), CSA approved, CE per IEC

Description	POP Catalog Number	Package Includes
10 A DIN SSR AC control	SSRDAC10	SSRDP8S10A1
10 A DIN SSR DC control	SSRDCC10	SSRDCCDS10A1
20 A DIN SSR AC control	SSRDAC20	SSRDP8S20A1
20 A DIN SSR DC control	SSRDCC20	SSRDCCDS20A1
10 A panel SSR AC control w/ TP	SSRTPAC10	SSRPP8S10A1 + SSRAT1 (1 pc)
10 A panel SSR DC control w/ TP	SSRTPDC10	SSRPP8S10A1 + SSRAT1 (1 pc)
25 A panel SSR AC control w/ TP	SSRTPAC25	SSRPP8S25A1 + SSRAT1 (1 pc)
25 A panel SSR DC control w/ TP	SSRTPDC25	SSRPP8S25A1 + SSRAT1 (1 pc)



10 A DIN mount
SSR, AC control



10 A DIN mount
SSR, DC control



20 A DIN mount
SSR, AC control



20 A DIN mount
SSR, DC control



10 A panel mount
SSR, AC control



10 A panel mount
SSR, DC control



25 A panel mount
SSR, AC control



25 A panel mount
SSR, DC control



- RoHS Compliant
- REACH Compliant
- Product Environmental Profile
- End-of-Life Instructions

Product selection tablet apps available on:



For more information, visit
www.schneider-electric.com/us
 and enter key code **i458u**

Enter key code

> OK



Schneider Electric USA

1415 S. Roselle Road
 Palatine, IL 60067
 Tel: 847-397-2600
 Fax: 847-925-7500
www.schneider-electric.com/us