

# Point-of-Purchase packaging provides convenient solutions for control, signaling, and relay products.

**Need to grab and go?** Visit your local Schneider Electric distributor today to grab the right products conveniently packaged together with all the selection and accessories you need. Point-of-Purchase packaging does all the thinking for you so that you can just grab what you need – and go!

## 30 mm products

### Features and benefits

- Heavy-duty pushbuttons, selector switches, and pilot lights for industrial applications
- Oiltight, watertight, and dustproof (rated for NEMA® Types 4 and 13 environments without boots)
- Includes multiple color inserts or legend plates (where applicable) — use what you need, discard what you don't
- Fingersafe® terminals for improved safety
- UL® listed, CSA® approved, CE per IEC®



30 mm pushbuttons



30 mm pilot light



30 mm control station

### 30 mm pushbuttons

Description	POP Catalog Number	Package Includes
30 mm pushbutton with contact block and multi colors	9001AB1	9001KR1U + KA1 + KN201 + KN202
30 mm push/pull mushroom	9001AB2	9001KR9R + 9001KA1
30 mm mushroom with legend	9001AB3	9001KR5R + KA1 + KN205
30 mm two-position selector switch with contact and legend	9001AS1	9001KS11B + 9001KA1 + 9001KN244
30 mm three-position selector switch with contact and legend	9001AS2	9001KS43B + 9001KA1 + 9001KN260

### Pilot light

Description	POP Catalog Number	Package Includes
Pilot light (KP)	9001AL1	9001KP1 + 9001R9 + 9001G9

### 30 mm control station

Description	POP Catalog Number	Package Includes
30 mm control station	9001AE3	9001BG201

## BW pendant station

### Features and benefits


- Easy to hold in one hand with contoured grip
- Single- or two-speed buttons
- Momentary or maintained contact
- Available with or without mechanical interlocks
- Yellow, black, or red enclosure options
- High-impact thermoplastic enclosure with self-extinguishing flammability rating (UL 94V)
- Oiltight, watertight, dustproof, and corrosion-resistant (rated for NEMA 1, 3, 3R, 4, 4X, and 13)
- UL listed, CSA certified, CE per IEC

Description	POP Catalog Number	Package Includes
BW pendant	9001BWP1	9001BW92Y



BW pendant

Make the most of your energy<sup>SM</sup>

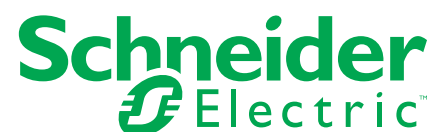

## 22 mm pushbuttons.....

### Features and benefits

- Simple, flexible, and robust pushbuttons, selector switches, control stations, and pilot lights for industrial applications
- Ideal for applications exposed to high-pressure cleaning, dust, and extreme temperatures
- Easy, secure mounting with a snap-fit head and body, tightened with a single screw
- UL Listed, CSA Approved, CE per IEC
- Rated for NEMA 1, 3, 3R, 4, 12, 13

Description	POP Catalog Number	Package Includes
22 mm pushbutton w/contact + six colors	XB4AB1	ZB4BZ101 + ZB4BA9
22 mm mushroom w/NC contact	XB4AB2	XB4BS542
22 mm two-position selector switch w/NO contact	XB4AS1	XB4BD21
22 mm three-position selector switch w/two NO contacts	XB4AS2	XB4BJ33
22 mm control station — mushroom w/NC contact	XALACS1	XALK178H7
22 mm control station — two button (start/stop) w/NO, NC contact	XALACS2	XALD211H29H7



22 mm pushbutton with contact block



22 mm mushroom button with contact block



22 mm 2-position selector switch



22 mm 3-position selector switch



22 mm mushroom control station



22 mm 2 button control station

## 40 mm tower light.....

### Features and benefits

- Up to five illuminated signaling units
- Steady light or flashing Super Bright LEDs
- Available in red, orange, green, blue, or clear
- Available with or without an audible buzzer (up to 85 decibels)
- Three screws for base mounting or aluminum support tube with a bracket
- UL recognized, CSA approved, CE per IEC

Description	POP Catalog Number	Package Includes
40 mm tower light (3) 24 VAC/VDC	XVCTL1	XVC4B3K



40 mm tower light

## Open style power relay.....

### Features and benefits

- Open frame power relay
- High-power contacts
  - » Up to 40 A switching
  - » Up to 2 HP motor load rating
- Riveted construction
- RoHS compliant
- UL Listed, CSA Approved, CE per IEC

Description	POP Catalog Number	Package Includes
40 A DPDT power relay, 120 VAC coil	8501CDPDT	8501CO16V20
40 A DPST power relay, 120 VAC coil	8501CDPST	8501CO7V20
40 A SPST power relay, 120 VAC coil	8501CSPST	8501CO6V20



40 A DPDT



40 A DPST



40 A SPST

## Slim interface relays, RSL and RSB

### Features and benefits

- An offer with maximum flexibility, comprising complete products and a single reference for a relay mounted on a socket
- Choice of sockets covering a range of voltages from 12 V to 230 V
- Conforms to international standards IEC/EN 61810-1, UL-508, CSA C22.2 N°14, GOST

Description	POP Catalog Number	Package Includes
SPDT slim relay and socket, screw terminal, 24 VAC/VDC coil	ASLSCR24	RSL1PVBU + RSLZ5
SPDT slim relay and socket, spring terminal, 24 VAC/VDC coil	ASLSPR24	RSL1PRBU + RSLZ5
SPDT slim relay and socket, screw terminal, 120 VAC/VDC coil	ASLSCR120	RSL1PVFU + RSLZ5
SPDT slim relay and socket, spring terminal, 120 VAC/VDC coil	ASLSPR120	RSL1PRFU + RSLZ5
SPDT PCB plug-in relay and socket, 24 VDC coil	RSB1SOC24D	RSB1A120BD + RSE1S35M + RZM031RB + RSZR215 + RSZL300
DPDT PCB plug-in relay and socket, 24 VDC coil	RSB2SOC24D	RSB2A080BD + RSE1S48M + RZM031RB + RSZR215 + RSZL300



SPDT slim relay & socket, screw 24 V



SPDT slim relay & socket, spring 24 V



SPDT slim relay & socket, screw 120 V



SPDT slim relay & socket, spring 120 V



SPDT PCB plug-in relay & socket 24 VDC



DPDT PCB plug-in relay & socket 24 VDC

## Plug-in style power relays, RPM and RXM

### Features and benefits

- General-purpose relay
- 15 A switching capacity
- Up to 1 hp motor load rating
- Complete system solution
  - » Relay, socket, protection module
  - » Ejector clip, ID tag
- RoHS compliant
- UL Listed, CSA Approved, CE per IEC

Description	POP Catalog Number	Package Includes
SPDT power plug-in relay and socket, 24 VDC coil	RPM1SOC24D	RPM12BD + RPZF1 + RPZR235 + RXM040W + RXZL520
SPDT power plug-in relay and socket, 120 VAC coil	RPM1SOC120A	RPM12F7 + RPZF1 + RPZR235 + RXM021FP + RXZL520
4PDT control plug-in relay and socket, 24 VDC coil	RXM4SOC24D	RXM4AB2BD + RXZE2M114 + RXM040W + RXZR335 + RXZL520
4PDT control plug-in relay and socket, 120 VAC coil	RXM4SOC120A	RXM4AB2F7 + RXZE2M114 + RXM021FP + RXZR335 + RXZL520



SPDT POWER plug-in relay & socket, 24 VDC



SPDT POWER plug-in relay & socket, 120 VAC



4PDT control plug-in & socket, 24 VDC



4PDT control plug-in & socket, 120 VAC

## Solid state relays

### Features and benefits

- Fingersafe — protects operators from live circuits
- Green LED — indicates line power
- Back-to-back SCRs — improves reliability when switching inductive loads
- Direct copper bonded (DCB) — enhances heat transfer for more efficient dissipation
- Internal snubber — protects relay against transients damaging internal circuitry for greater reliability
- Riveted base plate — increases safety in the event of a short circuit
- UL listed (DIN mount), UL recognized (panel mount), CSA approved, CE per IEC

Description	POP Catalog Number	Package Includes
10 A DIN SSR AC control	SSRDAC10	SSRDP8S10A1
10 A DIN SSR DC control	SSRDCC10	SSRDCCDS10A1
20 A DIN SSR AC control	SSRDAC20	SSRDP8S20A1
20 A DIN SSR DC control	SSRDCC20	SSRDCCDS20A1
10 A panel SSR AC control w/ TP	SSRTPAC10	SSRPP8S10A1 + SSRAT1 (1 pc)
10 A panel SSR DC control w/ TP	SSRTPDC10	SSRPP8S10A1 + SSRAT1 (1 pc)
25 A panel SSR AC control w/ TP	SSRTPAC25	SSRPP8S25A1 + SSRAT1 (1 pc)
25 A panel SSR DC control w/ TP	SSRTPDC25	SSRPP8S25A1 + SSRAT1 (1 pc)



10 A DIN mount  
SSR, AC control



10 A DIN mount  
SSR, DC control



20 A DIN mount  
SSR, AC control



20 A DIN mount  
SSR, DC control



10 A panel mount  
SSR, AC control



10 A panel mount  
SSR, DC control



25 A panel mount  
SSR, AC control



25 A panel mount  
SSR, DC control



- RoHS Compliant
- REACH Compliant
- Product Environmental Profile
- End-of-Life Instructions

### Product selection tablet apps available on:



For more information, visit  
[www.schneider-electric.com/us](http://www.schneider-electric.com/us)  
 and enter key code **i458u**

Enter key code

> OK



### Schneider Electric USA

1415 S. Roselle Road  
 Palatine, IL 60067  
 Tel: 847-397-2600  
 Fax: 847-925-7500  
[www.schneider-electric.com/us](http://www.schneider-electric.com/us)