



Product Catalog

for professionals

[Products](#) > 17522

17522 – 100A/RS 60PK

GE A21 - Rough Service

Print this Page

Convert to PDF

GENERAL CHARACTERISTICS

Lamp type	Incandescent - A-line
Bulb	A21
Base	Medium Screw (E26)
Primary Application	Rough Service
Filament	C-7A
Bulb Finish	Inside frost
Rated Life (NOM)	2000 hrs/5400 hrs
Bulb Material	Soft glass

PHOTOMETRIC CHARACTERISTICS

Initial Lumens (NOM)	1060 /800
Nominal Initial Lumens per Watt (NOM)	11/9

ELECTRICAL CHARACTERISTICS

Wattage (NOM)	100.0
Voltage (NOM)	130.0

DIMENSIONS

Maximum Overall Length (MOL) (NOM)	4.1300 in (104.9 mm)
Bulb Diameter (DIA) (NOM)	2.6250 in (66.6 mm)
Light Center Length (LCL) (NOM)	2.9100 in (73.9 mm)


PRODUCT INFORMATION

Product Code	17522
Description	100A/RS 60PK
Standard Package	Case
Standard Package GTIN	10043168175224
Standard Package Quantity	60
Sales Unit	Unit
No Of Items Per Sales Unit	1
No Of Items Per Standard Package	60
UPC	043168175227

CAUTIONS & WARNINGS

-


[See list of cautions & warnings.](#)

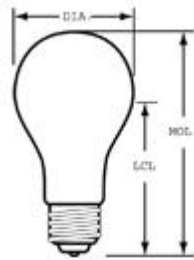

Bulb



Base

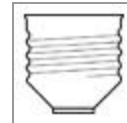

Filament



[View Larger](#)

ADDITIONAL RESOURCES

[MSDS \(Material Safety Data Sheets\)](#)

[Disposal Policies & Recycling Information](#)