



# Product Catalog

for professionals

[Products](#) > 15831

## 15831 – FLE15HT3/2/827

GE Soft White Spiral® T3 - Facilities; Retail Display; Hospitality; Office; Restaurant

Print this Page

Convert to PDF

**This product is no longer manufactured.**

- Up to 75% energy savings One piece unit screws directly into incandescent sockets T3 Spirals® lamps provide economical solution with small overall size

a product of  
**ecomagination**



- High Color Rendering
- cUL Listed
- Energy Savings
- UL Listed



### GENERAL CHARACTERISTICS

Lamp type	Compact Fluorescent - Self-Ballasted
Bulb	T3
Base	Medium Screw (E26)
ENERGY STAR® Qualified	Yes
Primary Application	Standard; Facilities; Retail Display; Hospitality; Office; Restaurant
Equivalent Wattage (NOM)	60 W
Rated Life (NOM)	10000 hrs
Starting Temperature (MIN)	-15 °C(5 °F)
Total Harmonic Distortion (THD) (NOM)	145 %
Mercury Content (NOM)	4 mg
Picograms of Mercury (NOM)	572 picograms Hg per mean lumen hour
<ul style="list-style-type: none"> <li>Contains Mercury, For more on clean up and safe disposal visit <a href="http://epa.gov/cfl">epa.gov/cfl</a></li> </ul>	

### PHOTOMETRIC CHARACTERISTICS

Initial Lumens (NOM)	950
Mean Lumens (NOM)	765
Nominal Initial Lumens per Watt (NOM)	63
Color Temperature (NOM)	2700 K
Color Rendering Index (CRI) (NOM)	82


### ELECTRICAL CHARACTERISTICS

Wattage (NOM)	15.0
Voltage (NOM)	120.0

Bulb



Base

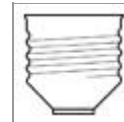

Package



[View Larger](#)

### ADDITIONAL RESOURCES

[Disposal Policies & Recycling Information](#)

### YOU MIGHT ALSO BE INTERESTED IN...

#### For Longer Life



[GE Spiral® T2](#)  
Product code: 86271

[COMPARE](#)

#### For Energy



[GE Spiral® T2](#)  
Product code: 86271

[COMPARE](#)

#### For Better Light



[GE Spiral® T2](#)  
Product code: 86271

[COMPARE](#)

#### For Safety



[GE Spiral® T2](#)  
Product code: 86271

[COMPARE](#)

Input Voltage (NOM)	120.0 V
Input Current (NOM)	0.23 A
Power Factor (NOM)	0.6

DIMENSIONS

Maximum Overall Length (MOL) (NOM)	4.8000 in (121.9 mm)
Nominal Length (NOM)	4.8000 in (121.9 mm)

PRODUCT INFORMATION

Product Code	15831
Description	FLE15HT3/2/827
Standard Package	Case
Standard Package GTIN	10043168158319
Standard Package Quantity	10
Sales Unit	Unit
No Of Items Per Sales Unit	1
No Of Items Per Standard Package	10
UPC	043168158312

⚠ CAUTIONS & WARNINGS

-

[See list of cautions & warnings.](#)

NOTES

- Best performance if operated base up and at 77 degrees F (25C) ambient temperature.
- Fluorescent lamp lumens decline during life
- Lumens on one piece self ballasted lamp systems are measured base up.
- Most one piece self ballasted lamps for incandescent sockets and plug-in lamps with screw-in adapters do not work with clip-on shades
- Use only on 120V 60 Hz circuits. Do not use on dimming circuits, photocells or timers. Do not use in wet locations.

For Super Long Life



[GE Soft White Biax® T3 - Facilities; Retail Display; Hospitality; Office; Restaurant](#)  
Product code: 12004

- Up to 75% energy savings One piece unit screws directly into incandescent sockets T3 Mini Biax(R) provides longest life with smallest overall size

- Super long life

COMPARE

For Environmental



[GE Soft White Biax® T3 - Facilities; Retail Display; Hospitality; Office; Restaurant](#)  
Product code: 12004

- Up to 75% energy savings One piece unit screws directly into incandescent sockets T3 Mini Biax(R) provides longest life with smallest overall size

- Super long life

COMPARE

\*Click on product for more specification details

[Return To Top](#)