




34835 Product Details

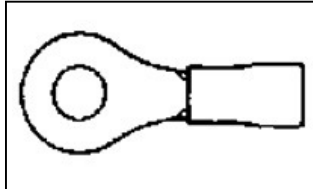

34835

TE Part Number: 34835

Active

[Add to Part List](#)

Ring and Spade Tongue Terminals

[Always EU RoHS/ELV Compliant \(Statement of Compliance\)](#)

Product Highlights:

- Terminal Shape = Ring Tongue
- Receptacle Style = Straight
- Body Style = PLASTI-GRIP
- Barrel Type = Closed Barrel
- Wire/Cable Type = Regular Wire

[View all Features](#) | [Find Similar Products](#)

[Previous](#) [1](#) ... [6](#) [7](#) [8](#) **[9]** [10](#) ... [20](#) [Next](#)

Quick Links

- [Check Pricing & Availability](#)
- [Search for Tooling](#)
- [Product Feature Selector](#)
- [Compare Products](#)
- [Contact Us About This Product](#)
- [Request Samples](#) **NEW!**

Documentation & Additional Information

Product Drawings:

- [TERMINAL, RING TONGUE, PLASTI-GRIP WIRE SIZE: 12-10 AWG](#) (PDF, English)

Catalog Pages/Data Sheets:

- [STANDARD TERMINALS AND SPLICES](#) (PDF, English)

Product Specifications:

- None Available

Application Specifications:

- [PLASTI-GRIP Terminals and Splices](#) (PDF, English)

Instruction Sheets:

- None Available

CAD Files:

- None Available

Additional Information:

- [Product Line Information](#)

Related Products:

- [Tooling](#)

[List all Documents](#)

Product Features (Please use the Product Drawing for all design activity)

Product Type Features:

- [Terminal Shape](#) = Ring Tongue
- [Receptacle Style](#) = Straight
- [Body Style](#) = PLASTI-GRIP
- [Barrel Type](#) = Closed Barrel
- [Wire/Cable Type](#) = Regular Wire
- [Insulation](#) = Yes
- [Insulation Support](#) = Insulation Support
- [Insulation Diameter \(mm \[in\]\)](#) = 6.35 [.250] Max.
- Stud Size = 4
- [Stud Diameter \(mm \[in\]\)](#) = 2.84 [0.112]
- [Shape](#) = RING-043
- [Heavy Duty](#) = No
- [Material](#) = Copper
- [Finish](#) = Tin
- Tongue Material Thickness (mm [in]) = 1.07 [0.042]
- Color = Yellow
- Insulation Material = Vinyl

Electrical Characteristics:

- Voltage (VAC) = 600

Body Related Features:

- [Wire Range \(mm \[AWG\]\)](#) = 3.00-6.00² [12-10]
- Wire Range (CMA) = 5,180 - 13,100

Industry Standards:

 
- Government/Industry Qualification = No
- [RoHS/ELV Compliance](#) = RoHS compliant, ELV compliant
- [Lead Free Solder Processes](#) = Not relevant for lead free process
- RoHS/ELV Compliance History = Always was RoHS compliant

Packaging Related Features:

- [Packaging Method](#) = Loose Piece

Other:

- Brand = AMP



[Provide Website Feedback](#) | [Need Help?](#)

[Home](#) | [Customer Support](#) | [Suppliers](#) | [Site Map](#) | [Privacy Policy](#) | [Browser Support](#)
© 2008 Tyco Electronics Corporation All Rights Reserved