

Solid as a rock

Soliroc™



SOLUTIONS FOR EXPOSED OR UNSUPERVISED ENVIRONMENTS

Think Soliroc™ for strength and design in exposed areas at the mercy of vandals and other abuse.

The IK 10 Soliroc™ guarantees brute strength with an appealing design aesthetic and can be used in locations such as:

- Sports & entertainment venues
- Offices
- Open spaces
- Warehouses
- Shops
- Schools
- Detention centres
- Medical facilities
- Childcare centres and many more...



OUTDOOR AREAS | Weatherproof switch



SHOP FRONTS | Keyswitch



PUBLIC WASHROOMS | Automatic switch



SPORTS FACILITIES | Illuminated pushbutton



WAREHOUSES | Arteor Socket + RJ 45 network socket



PARKS & GARDENS | Socket with locked cover



SCHOOLS | Arteor adaptor with cover



OFFICES | Pushbutton with label-holder



SHOPPING CENTRES | Arteor Socket

 
Safe, reliable and easy to install

Installing Soliroc™ is as easy as lego.
Combine with Batibox boxes for a simple and secure installation.

 


Legrand flush-mounting box BATIBOX

Dry partitions



Concrete



Masonry



3 FLUSH-MOUNTING BOX VERSIONS |

Accept all Soliroc functions



SOLIROC 1 AND 2 GANG SURFACE BOXES |

For surface-mounting installations



UNIVERSAL SUPPORT FRAME |

Just snap in any Soliroc mechanism
71 mm fixing centre



AUTOMATIC CONNECTION MECHANISMS |

10 switches and push
buttons come with automatic
terminals to save you
precious time on installation

FLUSH-MOUNTING BOXES

UNIVERSAL SUPPORTS



ARTEOR ADAPTOR OPTIONS |

- with cover
 - with cover and key
 - without cover
- For fitting Arteor functions



METAL ALLOY |

Finishing plate for guaranteed toughness in 1, 2 or 3 gang (horizontal or vertical mounting). Strong resistance against scratches, graffiti and lighter flames. Great resistance to salt - suitable for coastal areas

SMOOTH TRANSITION |

Between mechanism and cover plate, preventing a firm grasp on the device



BLANKING PLUGS |

To cover the 4 fixing points

IK 10

The promise of strength and durability

All Soliroc™ products have successfully undergone severe testing to ensure we can offer you maximum security.



IK 10: MAXIMUM IMPACT RESISTANCE | All Soliroc products can withstand impacts of 20 joules



IK 10: MAXIMUM PULL-OFF RESISTANCE | Rounded plate shape to prevent a firm grasp



IP 55: GUARANTEED WEATHERPROOF | On the main functions required for outdoor installations

Soliroc™ lighting control units



778 11



778 25

Soliroc™ other controls










778 74






697 95





Suitable for public buildings, unsupervised passageways, car parks and communal areas in buildings
High resistance to IK 10 impacts and humidity


Pack	Cat.Nos	Switches 10 AX - 250 V _~ - IK 10 - IP 55
1	778 11	 2-way switch
1	778 21	 Intermediate switch
1	778 12	 Illuminated 2-way switch Supplied complete with lamp Cat.No 676 66
1	778 14	 2-way indicator switch Supplied complete with lamp Cat.No 676 68
1	778 13	 2-way switch with label holder
1	778 22	 Double pole switch


1	778 93	Complete switch 10AX - 250V - IK 10 - IP 55 2-way switch  802 51 + 778 11 + 778 51
---	--------	---

		Automatic switches - IK 10 - IP 55 Infrared detection Detection range adjustable from 3 m to 10 m Horizontal detection angle: 180° Light level threshold adjustable from 3 to 1000 lux Time delay adjustable from one second to 16s with repetition of cycle as long as movement is detected Remote manual control possible with normally closed pushbutton Integrated self-protection against overloads and short-circuits Should preferably be installed in box depth 50 mm
1	778 25	With neutral, 3-wire 1000 W  For controlling lamps: - Up to 1000 W, incandescent and halogen 230 V _~ - Up to 500 VA, ELV halogen via ferromagnetic or electronic transformer - Fluo 500 VA Can control a ventilation appliance (100 VA max.)
1	778 27	Without neutral, 2-wire 400 W  Can be installed as a replacement for a conventional switch without additional wiring For controlling lamps: 40 W min. to 400 W max. incandescent, halogen 230 V _~ or ELV halogen with ferromagnetic or electronic transformer

1	778 41	Pushbuttons 6 A - 230 V_~ - IK 10 - IP 55  Two-way pushbutton NO-NC contact
---	--------	---

Pack	Cat.Nos	Time-delayed switch - IK 10 - IP 55
1	778 23	 Without neutral, 2-wire - 1000 W For controlling 1000 W incandescent and halogen lighting 230 V _~ , 400 VA ELV halogen fluo lighting For controlling a motor (eg: Ventilation) - 250 VA Time delay from 25 seconds to 15 minutes
		Keyswitches - IK 10 - IP 54 To be equipped with european key barrel Cat.No 697 95 To be fitted with flush-mounting boxes depth 50 mm
1	778 74	 2-position keyswitch 2 NO contacts - 6 A - 230 V Key can be removed in either position
1	778 75	 3-position key-operated pushbutton Changeover switch with off position - 6 A - 230 V Key can be removed in off position
1	697 95	 European key barrel. Supplied with 1 set of 3 keys.

1	778 68	Illuminated sign 230 V_~ - IK 10 - IP 55  Mechanism incorporating white LEDs and a pivoting window which can take pre-printed labels 2 choices of power rating (0,2 W or 1 W)
---	--------	--

1	778 67	Passage lighting - IK 10 - IP 55  For lighting a staircase, etc 250 V _~ Supplied complete with: - Soliroc plate 5 modules - 1 set of 4 blanking plugs that can be removed by drilling Mechanism: screw fixing in flush-mounting boxes, depth 40 mm Supplied with: - 16 white LEDs (2 W) - 1 x 5 modules Batibox support
---	--------	--

Soliroc™ sockets, cable outlets



778 91



778 50

Suitable for public buildings, unsupervised passageways, car parks, communal areas in buildings
High resistance to IK 10 impacts and humidity

Pack	Cat.Nos	Complete socket - IK 10 - IP 55*
1	778 94	1 gang - 10A 802 51 AR787AMMGN 778 80A 778 51
1	778 91	Network socket - IK 10 - IP 20 Cat.6 RJ 45 socket - FTP
1	778 50	Cable outlet - IK 10 - IP 55 Supplied with cable grip

Soliroc™ plates, surface-mounting boxes, accessories



778 51



778 80 + 5722 81

Pack	Cat.Nos	Plates - IK 10
1	778 51	1-gang plate 110 x 110 mm
1	778 52	2-gang plate 110 x 181 mm Horizontal or vertical mounting 71 mm fixing centres
1	778 53	3-gang plate 110 x 252 mm Horizontal or vertical mounting 71 mm fixing centres
		Accessories
5	778 96	Replacement blanking plugs Can only be removed by drilling Set of 4
		Seals for surface correction Made of foam to compensate for unevenness of the wall
1	778 85	For 1-gang plate
1	778 86	For 2-gang plate
1	778 87	For 3-gang plate
		Blanking plate 2 modules
		Arteor adaptors Take 2-module Arteor mechanisms (except special surface-mounting type)
1	778 80A	Adaptor with cover - IP 55* - IK 10
1	778 81	Adaptor without cover - IP 20
1	778 84A	Adaptor with cover and key - IP 55* - IK 10

* When flap is closed

Arteor™ mechanisms

Ideal for renovations and new installations in residential or commercial environments



The following Arteor adaptors support 2-module Arteor mechanisms.



Adaptor
without
cover



Adaptor
with
cover



Adaptor
with cover
and key

Arteor™ Mechanisms

Below is a small selection of Arteor™ mechanisms suitable for use with the Soliroc™ range.

50+
mechanisms
available



RCBO Single pole & neutral
30mA 16A 240V



Overdoor lighting units
Supplied with diffusers and LED



Electronic room thermostat
Adjustable range from 5°C to 30°C



Emergency stop mushroom head push-buttons With key or 1/4 turn



RJ sockets
Cat 6, 5E & telephone



Television sockets
75 ohm "F" connector



USB female socket
For connecting USB devices



HDMI socket
For digital HD audio/video connection




Socket outlet 240V
10A and 15A autoswitched socket

To view all the Arteor mechanisms available please see the Arteor catalogue or visit www.legrand.com.au.

universal supports


 
 


802 51

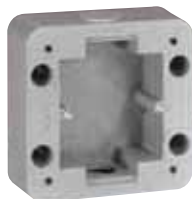

778 90

Supports for fixing Soliroc ranges in flush-mounting boxes

Pack	Cat.Nos	Batibox screw fixing support
10	802 51	<p>For 71 mm fixing centres Supplied with site protection Bi-material supports for enhanced rigidity Equipped with removable spacers for installation of Arteor</p> <p>For 1 gang - 2 modules Universal support for mounting on all types of screw-mounting boxes Can be used to make up multi-gang configurations by joining boxes vertically and horizontally</p> 
1	778 90	<p>Surface-mounting boxes Cannot be used for Cat.Nos 778 74/75 Supplied with 4 blanking plugs Take ISO 20 protective conductors</p> <p>1-gang 110 x 110 x 45 mm</p> 
1	778 92	<p>2-gang 110 x 181 x 45 mm Horizontal or vertical mounting 71 mm fixing centres</p> 

BATIBOX flush-mounting boxes



 



 
 
 
 

 
 
 


819 42



801 42



800 42

Pack	Cat.Nos	Boxes for concrete walls
50	81941A	 <p>A concrete box for 1-gang frame. 2 modules with screws.</p>
50	819 42	 <p>A concrete box for 2-gang passage way light only.</p>
20	819 72	 <p>Cover for concrete box.</p>
Pack	Cat.Nos	Boxes for masonry
100	801 08	 <p>Masonry round box for 1-gang frame. 2 modules. 40mm depth.</p>
100	801 51	 <p>Masonry square box for 1-gang frame. 2 modules. 50mm depth.</p>
40	801 42	 <p>Masonry square box for 2-gang frame. 2 modules and passage way light. 40mm depth.</p>
20	801 43	 <p>Masonry square box for 3-gang frame. 2 modules. 40mm depth.</p>
Pack	Cat.Nos	Boxes for dry partitions
50	800 41	 <p>Plasterboard box for 1-gang frame. 2 modules. 40mm depth.</p>
50	800 51	 <p>Plasterboard box for 1-gang frame. 2 modules. 50mm depth.</p>
40	800 42	 <p>Plasterboard box for 2-gang frame. 2 modules. 40mm depth.</p>
40	800 52	 <p>Plasterboard box for 2-gang frame. 2 modules. 50mm depth.</p>
20	800 43	 <p>Plasterboard box for 3-gang frame. 2 modules. 40mm depth.</p>
20	800 53	 <p>Plasterboard box for 3-gang frame. 2 modules. 50mm depth.</p>
1	800 67	 <p>Hole cutter \varnothing 67mm for Batibox flush-mounting boxes - dry partitions.</p>



HPM Legrand - Australia
Unit 2/79-99 St Hilliers Road
Auburn NSW 2144
Tel: 1300 369 777
Web: www.legrand.com.au

HPM Legrand - New Zealand
106 - 124 Target Road
Glenfield, Auckland 0627
Tel: 0800 476 009
Web: www.legrand.co.nz