



NEW

Legrand cabling system LCS² category 6 cables

Legrand cabling system LCS² category 6 cords

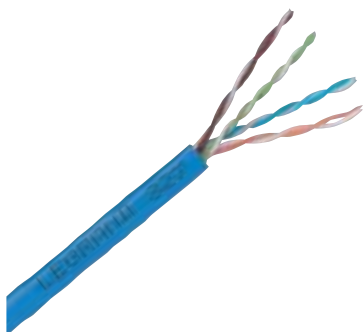

327 54

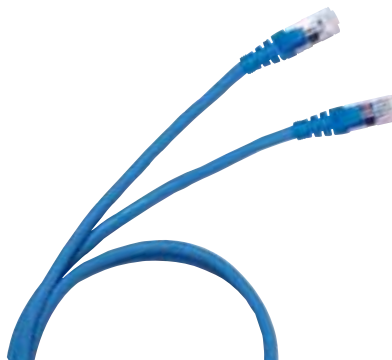

517 62

Pack	Cat.Nos	Cables for local networks cat. 6
		Cables 4 pairs or 2 x 4 twisted pairs 100 ohms Blue RAL 5015 Colour code TIA/EIA Conform to standards ISO/IEC 11801 Ed. 2.0, EN 50173-1 and TIA/EIA 568C
		U/UTP - 4 pairs
305 ⁽¹⁾	LSZH 327 54 PVC	Length 305 m Supplied in cardboard box. Weight 16 kg
500 ⁽¹⁾	328 61	Length 500 m Supplied on reel. Weight 18 kg
1000 ⁽¹⁾	328 71	Length 1000 m Supplied on reel
305 ⁽¹⁾	327 55	Length 305m Supplied in cardboard box. Weight 13 kg
500 ⁽¹⁾	328 62	Length 500 m Supplied on reel. Weight 19 kg
1000 ⁽¹⁾	328 72	Length 1000 m Supplied on reel
		U/UTP - 2 x 4 pairs
500 ⁽¹⁾	328 63	Length 500 m Supplied in cardboard box. Weight 38 kg
		F/UTP - 4 pairs
305 ⁽¹⁾	328 56	Length 305 m Supplied on reel. Weight 17 kg
500 ⁽¹⁾	327 56	Length 500 m Supplied on reel. Weight 25 kg
		F/UTP - 4 pairs
305 ⁽¹⁾	328 57	Length 305 m Supplied in cardboard box. Weight 17 kg
500 ⁽¹⁾	327 58	Length 500 m Supplied on reel. Weight 25 kg
		F/UTP - 2 x 4 pairs
50 ⁽¹⁾	327 76	Length 500 m Supplied on reel. Weight 48 kg
500 ⁽¹⁾	328 58	Length 500 m Supplied on reel. Weight 45 kg
		SF/UTP - 4 pairs
500 ⁽¹⁾	327 57	Length 500 m Supplied on reel. Weight 29 kg
500 ⁽¹⁾	327 59	Length 500 m Supplied on reel. Weight 30 kg
		SF/UTP - 2 x 4 pairs
500 ⁽¹⁾	328 59	Length 500 m Supplied on reel. Weight 52 kg

Pack	Cat.Nos	RJ 45 patch cords and user cords cat. 6
		RJ 45 - RJ 45 right U/UTP unscreened impedance 100 Ω
		PVC
1	517 72	Length 1 m
1	517 73	Length 2 m
1	517 74	Length 3 m
1	517 75	Length 5 m
		LSZH
1	518 62	Length 1 m
1	518 63	Length 2 m
1	518 64	Length 3 m
1	518 65	Length 5 m
		PVC
		F/UTP screened impedance 100 Ω
1	517 62	Length 1 m
1	517 63	Length 2 m
1	517 64	Length 3 m
5	517 65	Length 5 m
		LSZH
1	518 54	Length 1 m
1	518 55	Length 2 m
1	518 56	Length 3 m
1	518 57	Length 5 m
		PVC
		SF/UTP shielded impedance 100 Ω
5	517 52	Length 1 m
5	517 53	Length 2 m
5	517 54	Length 3 m
5	517 55	Length 5 m

(1) in metre(s)