


					
	VME VME64X CompactPCI®				
Home	About Vector	Distributors	Sales	Contact Us	Catalog Request

VME64x EUROCARD,6U, PLUGBORD™ PART NO. : 4616-1

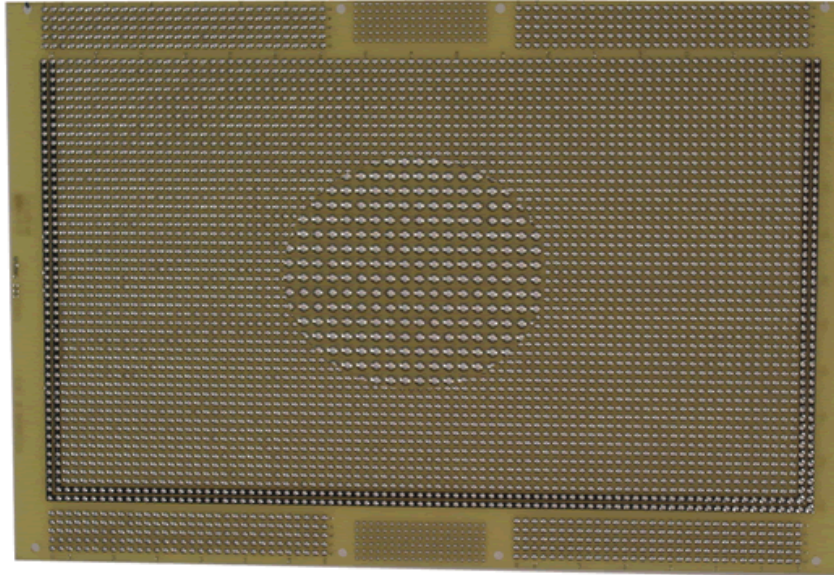

Description :

- 6U x 160mm, Hole Dia.: 0.042", Grid: 0.100" x 0.100", J1, J2, P0
- Pad Per Hole
- V & G busses
- For 160 - Pin DIN Connectors
- Pad and bus surfaces solder-coated for user convenience
- Plated-thru holes
- Row and column legends provided
- Layout paper..... [Layout Paper\(PDF\)](#)

Circuit Pattern :	Pad Per Hole
16 Pin DIP Capacity :	105
Hole Diameter :	0.042" { 1.0668 mm }
Grid :	0.100" x 0.100" { 2.54mm X 2.54mm }
Dimension { H, W, T } :	9.19" x 6.30" x 0.062" -----> { 6U x 160mm }
Material :	FR4 Epoxy Glass { MIL - P13949 type Gf }
Wire-Wrap Terminals :	T44, T46, T49 & T68
160 Pin DIN Connector :	RE160MSR { Available Separately }
Wire-Wrap Socket Pins :	R32
Recommended Card Cage:	CCK28-84-00 Series Card Cage { Subracks }
UL Flammability Class :	94V - 0

email us your requirements : inquire@vectorelect.com

11115 Vanowen St., North Hollywood, CA - 91605, USA

Tel: (818) 985 8208, (800) 423 5659; Fax: (818) 985 7708

Circbord®, Vectorbord® and VectorPak® are registered trademarks of Vector Electronics & Technology, Inc.
CompactPCI® is a registered trademark of PCIMG. © 2001 Vector Electronics & Technology, Inc. - All Rights Reserved

webmaster@vectorelect.com

