
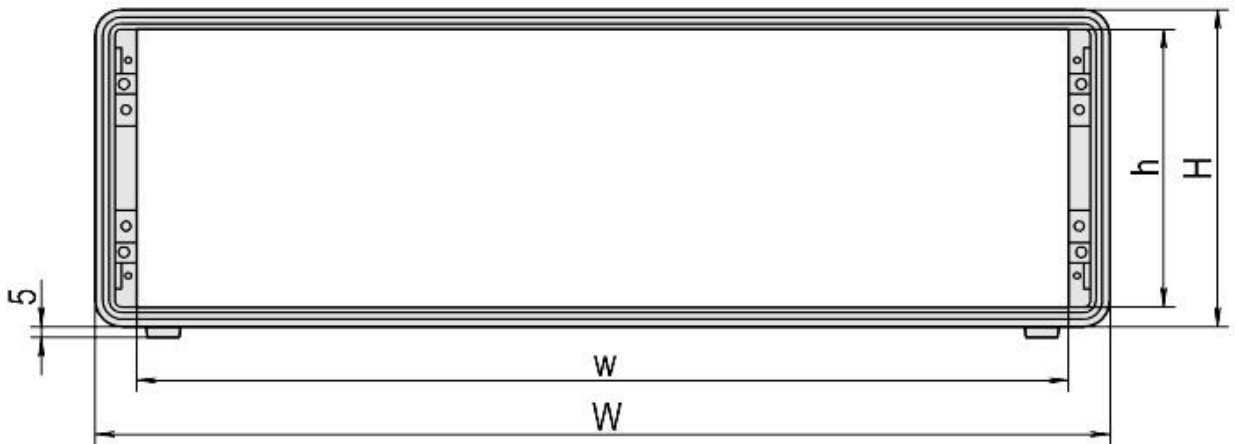


Schroff Compac Pro case dimensions

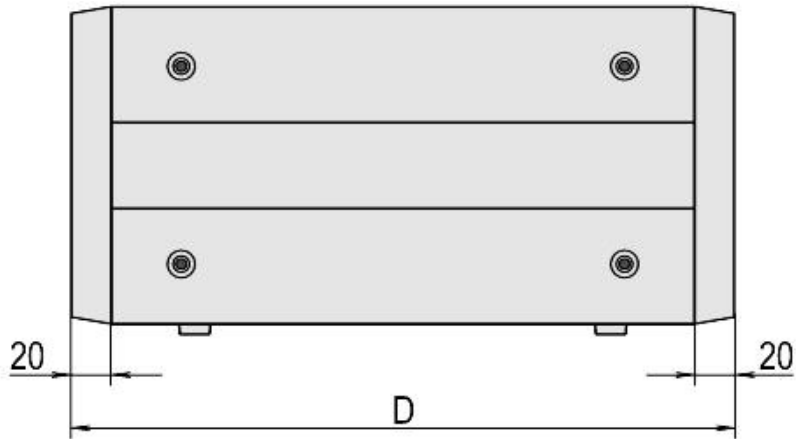

RS stk no	Schroff part	Height	Width	W (mm)	w (mm)	H (mm)	h (mm)	D (mm)
7212792	14575023	2 U	42 HP	257	219	102.6	84.4	271
7212796	14575123	3 U	42 HP	257	219	147.1	129.3	271
7212806	14575143	3 U	63 HP	364	326	147.1	129.3	271
7212809	14575171	3 U	84 HP	471	432	147.1	129.3	511
7212803	14575243	4 U	63 HP	364	326	191.6	173.8	271
7212812	14575245	4 U	63 HP	364	326	191.6	173.8	331
7212815	14575247	4 U	63 HP	364	326	191.6	173.8	391
7212819	14575271	4 U	84 HP	471	432	191.6	173.8	511