


Part Number:

CM1450

Type	Size	Rating	Description
Incandescent	G11	24V 35mA	G-3½ Bayonet Lamp

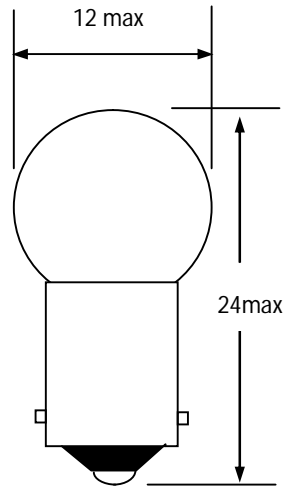

Dimensions in millimetres

TEST VOLTS	CURRENT (mA)			LIGHT OUTPUT (Lm)			LIFE Hours
	Min.	Nom.	Max.	Min.	Nom.	Max.	
24	31	35	39	2.2	2.9	3.6	3,000

Notes:

- 1 **Base Type** BA9s/13 Nickel plated brass in accordance with BS EN 60061-1
- 2 **Filament Shape** C-2F
- 3 **Lamp Marking** CML1450 24V 35mA
- 4 **Environmental** RoHS & REACH SVHC compliant