

PANEL MOUNT INDICATOR, NON-RELAMPABLE

LED TECHNOLOGY


MOUNTING HOLE, Ø 0.500"

| PART NO. | LENS COLOR | VOLTAGE | CURRENT [mA] | RATED LIFE HOURS |
|-----------------------|------------|---------|----------------------------|------------------|
| LED 6V SERIES | | | | |
| WL-6391Q2M1-6V | RED | 5V-6V | 20mA | 100,000 |
| WL-6391Q2M3-6V | AMBER | 5V-6V | 20mA | 100,000 |
| WL-6391Q2M5-6V | GREEN | 5V-6V | 20mA | 100,000 |
| WL-6391Q2M6-6V | BLUE | 5V-6V | 20mA | 100,000 |
| WL-6391Q2M4-6V | WHITE | 5V-6V | 20mA | 100,000 |
| LED 12V SERIES | | | | |
| WL-6391Q2M1-12V | RED | 12V-14V | 20mA | 100,000 |
| WL-6391Q2M3-12V | AMBER | 12V-14V | 20mA | 100,000 |
| WL-6391Q2M5-12V | GREEN | 12V-14V | 20mA | 100,000 |
| WL-6391Q2M6-12V | BLUE | 12V-14V | 20mA | 100,000 |
| WL-6391Q2M4-12V | WHITE | 12V-14V | 20mA | 100,000 |
| LED 24V SERIES | | | | |
| WL-6391Q2M1-24V | RED | 24V-28V | 20mA | 100,000 |
| WL-6391Q2M3-24V | AMBER | 24V-28V | 20mA | 100,000 |
| WL-6391Q2M5-24V | GREEN | 24V-28V | 20mA </td <td>100,000</td> | 100,000 |
| WL-6391Q2M6-24V | BLUE | 24V-28V | 20mA | 100,000 |
| WL-6391Q2M4-24V | WHITE | 24V-28V | 20mA | 100,000 |

NOTES

1. Recommended panel thickness
0.031" to 0.125"
2. .250 x .020 terminals are standard
3. Storage temperature
 T_{STG} : -25°C - +80°C
4. Ambient temperature
 T_A : -20°C - +60°C
5. Voltage tolerance
 V_{OP} : ±10%
6. DC operation only
7. Body material
Polycarbonate, white
8. Lens material
Polycarbonate
9. Bezel material
Stainless steel
10. Terminals
Quick-connect, tinned brass
11. Gaskets
Buna-N
12. Mounting hardware (nut, lock washer, and gasket) included

DIMENSIONAL CHARACTERISTICS

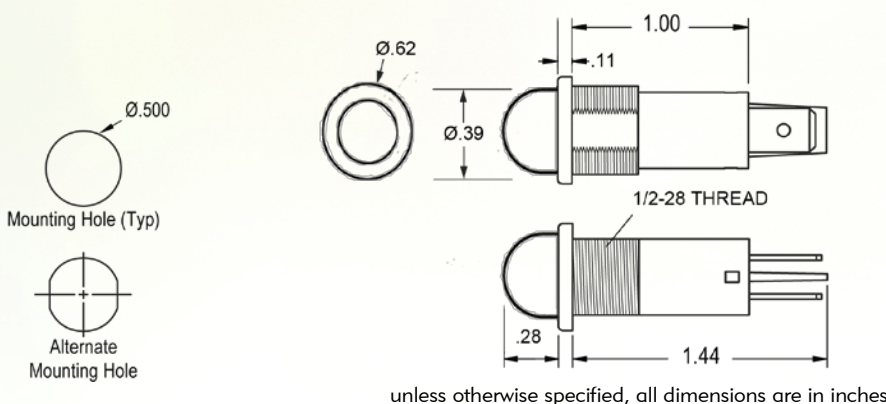

CERTIFICATIONS

UL (E340667), RoHS



- Splash proof
- Outdoor applications
- NEMA 3-R



OPTIONS

Additional options and lens styles available. Please contact Wamco for more information.