




## Electrode and probe holders S5 Part number 79696006



- Level control accessories

	Type	Accessories	Operating temperature (o C)	Pressure
79696044	S8	Light and compact 3-probe electrode holder (stainless steel) ? Electrode holder and 1000 mm probe? Especially recommended for drinks dispensers and for applications where space is limited	80	2 kg/cm 2
79696014	S3	Electrode holder with a single probe supplied in a standard length of 1000 mm. (304 stainless steel) ? Mounting with external 3/8" BSP thread and hexagonal head. Use 24 mm. spanner for hexagon. Suitable for use on boilers, autoclaves	≤ 200	Max.: 25 Kg/cm2
79696043	S7	Protected electrode for mounting by suspension.? Protective shell: PUC (S7) ? Electrode: stainless steel? Length of cable as requested (ref. C1) : 79 696 001		*** TRADUCTION MANQUANTE ***
79696006	S5	Suitable for high pressures and high temperatures.? Metal parts of stainless steel, isolated by ceramic.? 3/8" BSP mounting thread.	≤ 350	Max.: 15 Kg/cm 2

### Dimension Diagram : S5

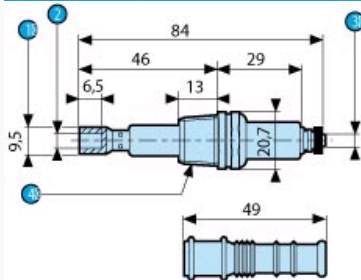

N°	Legend
1	9.5 Across flats
2	1/4 width
3	5/32 width
4	3/8 tapered NPT