


# E2/000 | e-chains® 2600-2700 | Accessories


Mounting brackets, polymer | pivoting | locking

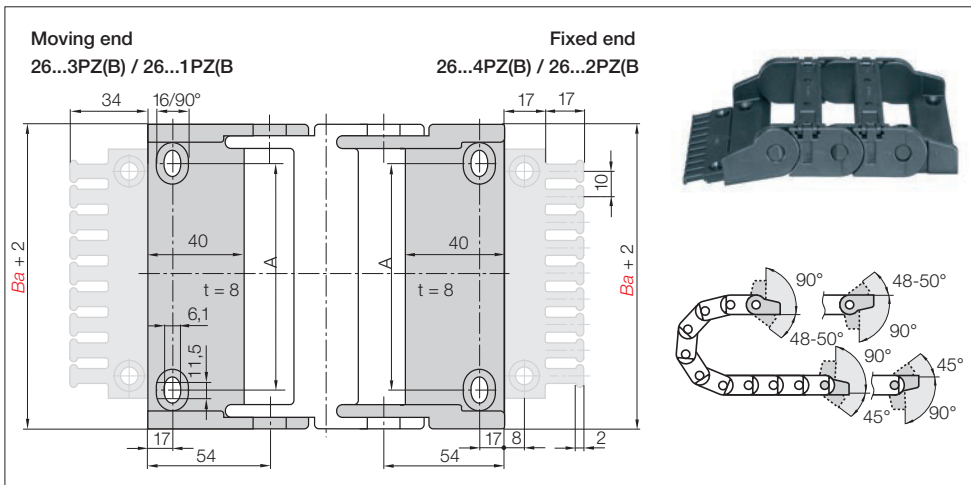

**Polymer pivoting** | Recommended for unsupported and gliding applications | **Standard Polymer locking** | Recommended for vertical hanging and standing applications

| Width Index | Standard | Part No. full set <b>pivoting</b> : |                        | Part No. full set <b>locking</b> : |                        | Dim. A [mm] | Number of teeth |
|-------------|----------|-------------------------------------|------------------------|------------------------------------|------------------------|-------------|-----------------|
|             |          | with tiewrap plates                 | without tiewrap plates | with tiewrap plates                | without tiewrap plates |             |                 |
| .05.        | ▶        | 2605.34PZB                          | 2605.34PZ              | 2605.12PZB                         | 2605.12PZ              | 30          | 5               |
| .06.        | ▶        | 2606.34PZB                          | 2606.34PZ              | 2606.12PZB                         | 2606.12PZ              | 45          | 5               |
| .07.        | ▶        | 2607.34PZB                          | 2607.34PZ              | 2607.12PZB                         | 2607.12PZ              | 55          | 7               |
| .09.        | ▶        | 2609.34PZB                          | 2609.34PZ              | 2609.12PZB                         | 2609.12PZ              | 70          | 9               |
| .10.        | ▶        | 2610.34PZB                          | 2610.34PZ              | 2610.12PZB                         | 2610.12PZ              | 80          | 10              |
| .12.        | ▶        | 2612.34PZB                          | 2612.34PZ              | 2612.12PZB                         | 2612.12PZ              | 105         | 12              |
| .15.        | ▶        | 2615.34PZB                          | 2615.34PZ              | 2615.12PZB                         | 2615.12PZ              | 130         | 15              |
| .17.        | ▶        | 2617.34PZB                          | 2617.34PZ              | 2617.12PZB                         | 2617.12PZ              | 155         | 17              |

Full set with tiewrap plate + 10 cable tiewraps, please add index **K1** ▶ e.g. 2605.34PZBK1

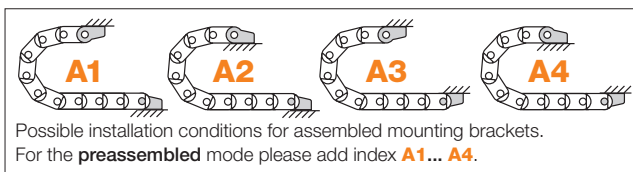

Part No. structure

2605.34PZB A1

A... must be indicated on preassembled configurations

With strain relief tiewrap plates

Full set pivoting = 34

Mounting bracket for selected width index



**Strain relief** e.g. clamps, tiewrap plates, nuggets and plug-in clips are available from stock. The complete chainfix range with order options ▶ from page 656