

# SKH-EA

## Revolving Warning Light



Model **DEB LED Lamp**  
**Recommended Product**  
 For more details on Model DEB  
 Refer to the "Replacement Bulb"  
 Section at the end of this Catalog




 **Bulb**

**IP23**

**Ø100**

## Best-selling Revolving Warning Light for wide range of applications.


### FEATURES

- Indoors allows upright, inverted, and sideways installation; outdoors allows upright installation only.
- Has the CE mark and conforms to the requirements (for 12V, 24V type only) for the EC directive.
- Dome is made from superior weather-resistant and light-translucent acrylic resin.
- Rotating parabolic reflector to enhance visibility from a distance.
- Vibration-resistant automobile bulb for extended bulb life.
- Available Colors are Red, Amber, Green, and Blue.


### Specifications

Series	Model	Rated Voltage	Current Consumption	Flash Rate (fpm)	Bulb		Mass
					Ratings	Repl. No.	
USA Version	SKH-12EA	DC 12V	0.8A	170	12V 10W	9	400g
	SKH-24EA	DC 24V	0.5A		24V 10W	10	
	SKH-120EA	AC 120V	0.07A		12V 5W	12	600g
Standard Version	SKH-12EA	DC 12V	0.8A		12V 10W	9	400g
	SKH-24EA	DC 24V	0.5A		24V 10W	10	
	SKH-100EA	AC 120V	0.065A		12V 5W	12	600g
	SKH-200EA	AC 200V	0.03A				

### How to Order

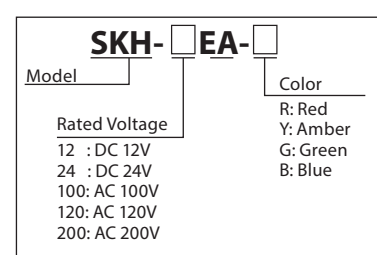

### Dimensions

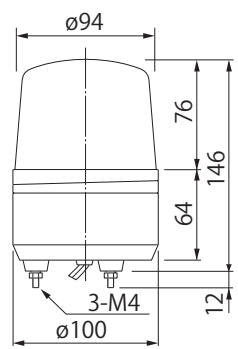

### Mounting Dimensions

