



Model Number


1/4" NPT-V124-G-S-.076M

Male receptacle, 1/2" UNF / 1/4" NPT, 4-pin

Features

- Front/screw mounting
- Operating voltage AC

Dimensions

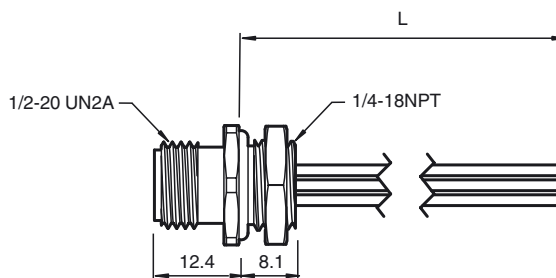

Technical data

General specifications

Number of pins	4
Construction type	straight
Connection 1	Male connector
Threading 1	1/2"
Connection 2	cable end
Threading 2	1/4"

Electrical specifications

Operating voltage	U_B	max. 300 V AC / DC
Operating current		4 A

Ambient conditions

Ambient temperature	-40 ... 105 °C (-40 ... 221 °F)
---------------------	---------------------------------


Mechanical specifications

Degree of protection	IP67
Connection	Single strand leads
Material	brass, nickel-plated
Contacts	gold plated copper alloy
Sleeve connector	Polyamide (PA)
Cable	
Cores	4 x 0.34 mm ²
Length	L 0.076 m
Note	1/4" (6.250mm) - 18 NPT installation thread

Approvals and certificates

UL approval	cULus Listed, General Purpose
-------------	-------------------------------

Electrical connection

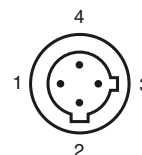

Electrical connection

1	RD/BK
2	RD/WH
3	RD
4	GN/YE