



Security Tech Germany

# Laminated 41 Series


## Corrosion-Resistant Steel

ABUS laminated steel padlocks provide an ideal solution for securing job boxes along with a variety of other industrial applications and excel in harsh environments.

## Key Features

- 5-pin cylinder offers maximum number of key differs and is non-key-retaining
- Comes with 2 keys per lock, but can be ordered with 1 key per lock
- Steel shackle and body plates are individually coated with non-hazardous, cadmium-free ETERNA™ plating for rust protection
- Vinyl bumper provides easy identification and added protection
- Padlocks are made from high-quality recycled steel
- FDA-approved lubrication is ideal for use in the food industry
- Packaging and labels made from 100% recycled materials
- Meets OSHA Lockout/Tagout Guidelines
- Made in Germany

## Specifications

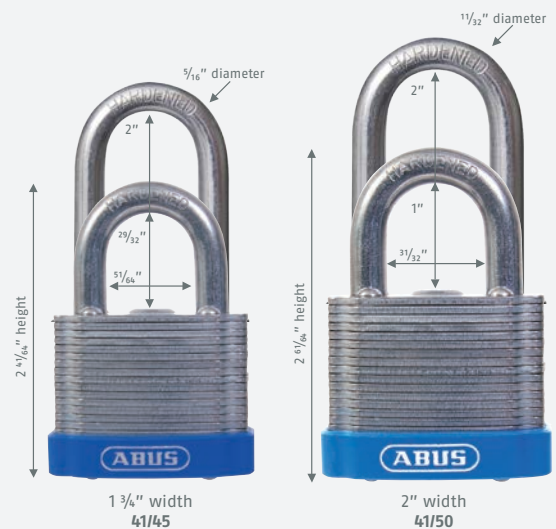

Product Description	Shackle Height	Body Width	#Pins in Cyl.	Key Options	Shackle Material
41/30	5/8"	1 1/4"	4 or 5	KA, KD, MK, GMK	ETERNA™-plated Steel
41/30HB50	2"	1 1/4"	4 or 5	KA, KD, MK, GMK	ETERNA™-plated Steel
41/40	3/4"	1 1/2"	4 or 5	KA, KD, MK, GMK	ETERNA™-plated Steel
41/40HB50	2"	1 1/2"	4 or 5	KA, KD, MK, GMK	ETERNA™-plated Steel
41/45	29/32"	1 3/4"	4 or 5	KA, KD, MK, GMK	ETERNA™-plated Steel
41/45HB50	2"	1 3/4"	4 or 5	KA, KD, MK, GMK	ETERNA™-plated Steel
41/50	1"	2"	4 or 5	KA, KD, MK, GMK	ETERNA™-plated Steel
41/50HB50	2"	2"	4 or 5	KA, KD, MK, GMK	ETERNA™-plated Steel

