



PROTECTIVE INDUSTRIAL PRODUCTS

148-1000 Specification Sheet

TOP GRAIN GOATSKIN PROTECTOR

PRODUCT DESCRIPTION:

Top grain Goatskin leather protector for Novax gloves, driver glove with fourchettes and set-in thumb, unlined, keystone thumb, zig zag elastic sewn inside on the back.

- Top grain goatskin leather.
- Consistent grading and superior workmanship.
- Elastic back closure for a snug fit.

Applications:

Cover glove to be used only for mechanical protection for rubber insulating gloves. Not to be used for electrical protection per ASTM F696-02.



TECHNICAL DATA:

Material: Goatskin leather

Construction: 100% leather

Color: Natural

Cuff Style: Slip on

Available Sizes: 7-12

Packaging: 12 pair per dozen, 6 dozen per case

Case Dimensions: (7) cm - 40 x 25 x 27 / in - 15.7 x 9.8 x 10.6
 (8) cm - 40 x 25 x 27 / in - 15.7 x 9.8 x 10.6
 (9) cm - 42 x 25 x 27 / in - 16.5 x 9.8 x 10.6
 (10) cm - 43 x 27 x 28 / in - 16.9 x 10.6 x 11.0
 (11) cm - 43.5 x 27 x 28 / in - 17.1 x 10.6 x 11.0
 (12) cm - 43.5 x 27 x 28 / in - 17.1 x 10.6 x 11.0

Case Weight: 23.8 lbs / 10.8 kg

Country of Origin/Harmonization Code: China/4203.29.3010

DIMENSIONS:

<u>Size Available</u>	<u>7</u>	<u>8</u>	<u>9</u>	<u>10</u>	<u>11</u>	<u>12</u>
Over Length (cm) – A	23.5	24.5	25.0	26.0	27.0	28.5
(in)	9.3	9.6	9.8	10.2	10.6	11.2
Palm Width (cm) – B	12.2	12.5	13.5	14.0	14.5	15.0
(in)	4.8	4.9	5.3	5.5	5.7	5.9


Leather Thickness

← 0.8 - 1.0 mm →

Binding color

Sky blue Red Green Brown Blue Black

<u>BARCODE #</u>	<u>DOZEN</u>	<u>CASE</u>
148-1000/12	01616314057846	02616314057845
148-1000/11	01616314045584	02616314045583
148-1000/10	01616314045577	02616314045576
148-1000/9	01616314045560	02616314045569
148-1000/8	01616314045553	02616314045552
148-1000/7	01616314049094	02616314049093

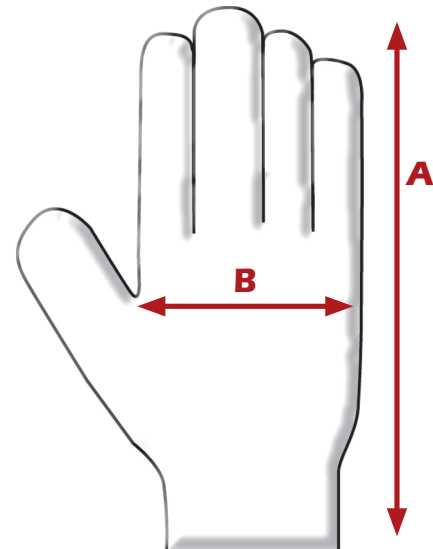

This document is the property of PIP and the information contained herein is proprietary to PIP.