



PROTECTIVE INDUSTRIAL PRODUCTS

Adversary Specification Sheet

SAFETY EYEWEAR

PRODUCT DESCRIPTION:

Adversary safety eyewear, semi-rimless, glossy frame, rubber temples, one piece bridge, enclosed lanyard.

- Sleek design with 8-base lens curve;
- Exceeds ANSI Z87.1+ High Impact Requirements;
- Scratch resistant coating;
- Soft nose piece, rubber temples and lightweight design provide user with a comfortable fit.

Applications:

Used for general manufacturing and anywhere eye protection is needed.

TECHNICAL DATA:

Base Curve: 9

Packaging: 12 units per box, 144 units per case

Case Dimensions (cm): 64 x 29.5 x 33 / (in): 25.2 x 11.6 x 13.0

Case Weight: 14.4 lbs / 6.5 kg

Manufacturer Certifications: ISO9001:2000 certified

Country of Origin/Harmonization Code: Taiwan/9004.90.0000




Polycarbonate lenses block 99.9% of the sun's ultraviolet rays. This ultraviolet protection has already been incorporated within the lens material when the lenses are being produced.

Item #	Lens Material	Lens Color	Lens Coating	Frame Design	Frame Color	UPC # Box	UPC # Case
250-28-0000	Polycarbonate	Clear	Hard-coat	Semi-rimless, glossy, rubber temples, one piece bridge	Black temples	01616314065834	02616314065833
250-28-0001	Polycarbonate	Gray	Hard-coat	Semi-rimless, glossy, rubber temples, one piece bridge	Black temples	01616314065827	02616314065826
250-28-0002	Polycarbonate	Clear	Indoor/outdoor	Semi-rimless, glossy, rubber temples, one piece bridge	Black temples	01616314068941	02616314068940
250-28-0003	Polycarbonate	Light blue	Hard-coat	Semi-rimless, glossy, rubber temples, one piece bridge	Black temples	01616314065841	02616314065840
250-28-0006	Polycarbonate	Silver	Mirror	Semi-rimless, glossy, rubber temples, one piece bridge	Black temples	01616314068927	02616314068926
250-28-0009	Polycarbonate	Amber	Hard-coat	Semi-rimless, glossy, rubber temples, one piece bridge	Black temples	01616314068934	02616314068933
250-28-0020	Polycarbonate	Clear	Anti-fog	Semi-rimless, glossy, rubber temples, one piece bridge	Black temples	01616314065810	02616314065819
250-28-0021	Polycarbonate	Gray	Anti-fog	Semi-rimless, glossy, rubber temples, one piece bridge	Black temples	01616314068958	02616314068957

DIMENSIONS:

Size Available	One size
Over Length (mm) – A	165
(in)	6.5
Lens Height (mm) – B	46
(in)	1.8
Over Width (mm) – C	134
(in)	5.2

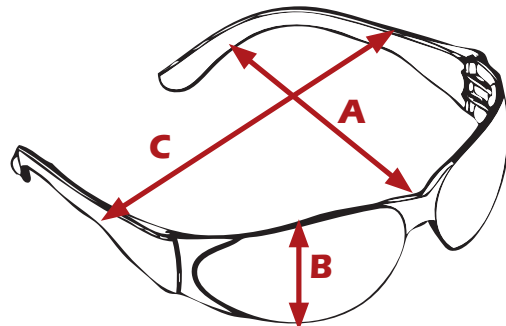

This document is the property of PIP and the information contained herein is proprietary to PIP.

Protective Industrial Products | 26 Computer Drive East | Albany, NY 12205
Phone: 518-861-0133 | Toll free: 800-262-5755 | Fax: 518-861-0144 | www.pipusa.com | sales@pipusa.com