



PROTECTIVE INDUSTRIAL PRODUCTS

33-G115 Specification Sheet

SEAMLESS KNITS FOR GENERAL DUTY

PRODUCT DESCRIPTION:

Gray polyurethane coated palm & fingers on gray seamless knit polyester.

- Seamless knit nylon for great dexterity
- Polyurethane coated palm and fingers for abrasion resistance
- Breathable back for comfort
- Pair packed for ease of distribution

Applications:

Used for electronic & computer assembly, quality control, inspection and general assembly.

TECHNICAL DATA:

Material: Polyester with polyurethane coating on palm and fingers

Color: Gray

Cuff Style: Continuous knit

Available Sizes: S - XXL

Packaging: 1 pair per bag, 12 pairs per dozen, 25 dozen per case

Case Dimensions (cm): 63 x 28 x 46 / (in): 24.8 x 11.0 x 18.1

Case Weight: (XS) 14.2 lbs / 6.4 kg (L) 17 lbs / 7.7 kg
(S) 15.6 lbs / 7.1 kg (XL) 18 lbs / 8.2 kg
(M) 16 lbs / 7.3 kg (XXL) 19.1 lbs / 8.7 kg

Country of Origin/Harmonization Code: China/6116.10.6500

Laundering Instructions:

Recommend washing gloves in slightly warm water not exceeding 40° C. A mild non-ionic detergent should be used. A 5-10 minute cycle time should be employed. Tumble dry on low - maximum temperature 140° F (60° C)




DIMENSIONS:

Size Available	XS	S	M	L	XL	XXL
Over Length (cm) – A	21.5	23	24	25	26	27
Tolerance +/- 0.8 (in)	8.46	9	9.4	9.8	10.2	10.6
Palm Width (cm) – B	9	9.2	9.5	9.8	10.2	11
Tolerance +/- 0.5 (in)	3.5	3.6	3.7	3.8	4	4.3
Hem Color	Purple	Red	Yellow	Brown	Black	Blue

PERFORMANCE PROPERTIES:

EN388: 3121

Abrasion	0	1	2	3	4	
Cut	0	1	2	3	4	5
Tear	0	1	2	3	4	
Puncture	0	1	2	3	4	

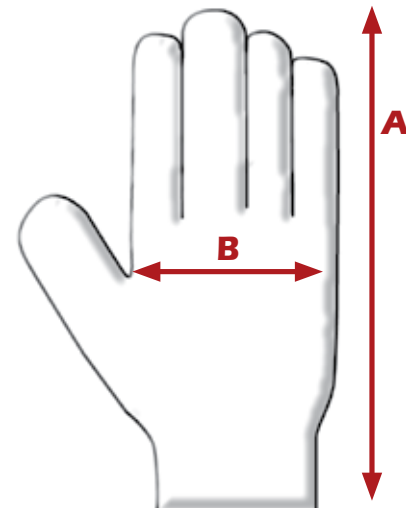

BARCODE #	DOZEN	CASE
33-G115/XXL	01616314124883	02616314124882
33-G115/XL	01616314124869	02616314124868
33-G115/L	01616314124838	02616314124837
33-G115/M	01616314124845	02616314124844
33-G115/S	01616314124852	02616314124851
33-G115/XS	01616314124876	02616314124875

This document is the property of PIP and the information contained herein is proprietary to PIP.